

# Antistatic brush

Stock

## ABL With specially woven steel bristles



### - Standard version

#### - Materials:

Spine: aluminium (unpainted)

Bristles: Specially woven steel

Woven steel  
bristles

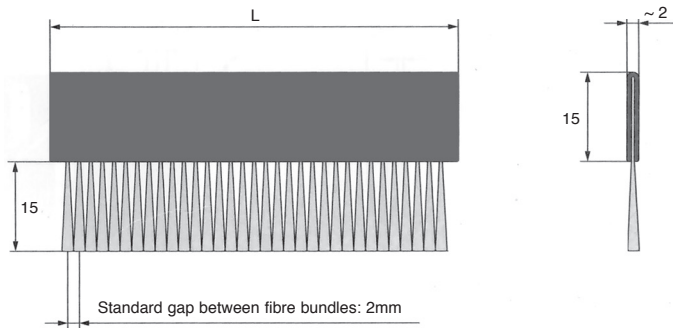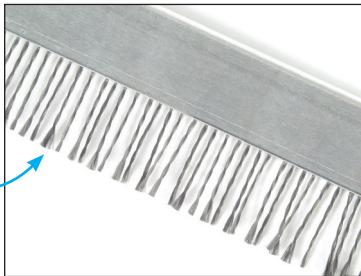

### DISCOUNTS

Qty	1+	4+	6+	10+
Disc.	List	-10%	-15%	On request

Part number	Length L (mm)	Fibre material	Fibre Ø (mm)	Stock*	Price each 1 to 3
ABL100005-K1	1000	Steel	0,012	✓	48,98 €

\*Depending on availability - Dimensions in mm

HPC

WEB  
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

## Our other products



BCH\_SS

Mushroom headed button, M3 to M8



MLY\_SS

Stainless steel bow shackle with eye bolt, Stainless steel



BPPL

Assembly tool for carrier ball, Mounting tool



GAL\_25

Ø25 conveyor roller, Without ball bearing



BOX-INS-W

Box set of self tapping inserts, Boxed set - For wood



PSPD40

Flexible tube handle, Black PVC



Q7

Angular contact ball bearing, Steel



PML

Solid foot mount for heavy loads, Ø 100, 120 or 150



T10\_21\_AL

T type timing pulley, Economy range - T10 aluminium



BOX-TOR-C

Box set of Nitrile O-rings in nitrile, 3.00 x 1.50mm to 30.20 x 3.00



BPL

Ball transfer unit light duty, Light



MFBC

Flexible Bellows coupling, Aluminium and Bronze - with clamping jaw

## Complementary products



ABL100000

Antistatic brush, For sensitive surfaces