

Antistatic brush

Stock

ABL With specially woven steel bristles


- Standard version

- Materials:

Spine: aluminium (unpainted)

Bristles: Specially woven steel

Woven steel
bristles

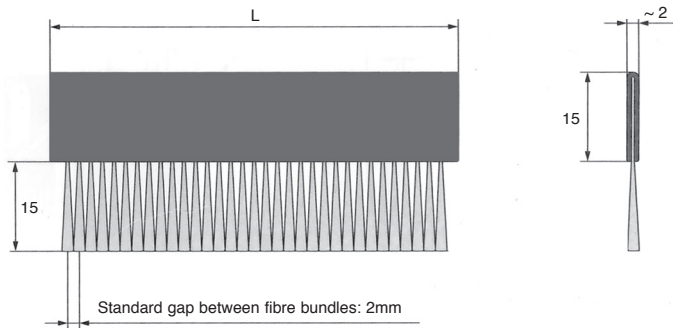

DISCOUNTS

Qty	1+	4+	6+	10+
Disc.	List	-10%	-15%	On request

Part number	Length L (mm)	Fibre material	Fibre Ø (mm)	Stock*	Price each 1 to 3
ABL100005-K1	1000	Steel	0,012	✓	48,98 €

*Depending on availability - Dimensions in mm

HPC

WEB
04/2020

www.hpceurope.com

 
Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

Our other products



RPP

Connecting plate for RPP type timing belts, RRP5



EZYS

Stainless steel cylindrical stop, stainless steel



NSB

Standard linear bearing housing, Closed - Long



VEL

Self-gripping cable strip, electric and pneumatic cables



KB_UU

Closed linear precision bearing, Precision - steel




CHTRP

Single and dual output gearboxes, Up to 9,1 Nm



PW_PWG3

Wheel - precision range, Bronze

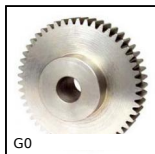


G0

Steel spur gear, Steel 20NCD2



UGAC_UGET

 Connection for threaded actuator rod, Connection for



GPLac

Brush, steel



ZDB

Machined plastic bevel gear , 2:1



T5M_T10M

T type timing belt per metre, T5 Steel cored polyurethane

Complementary products



ABL100000

Antistatic brush, For sensitive surfaces