

Antistatic brush

Stock

ABL With specially woven steel bristles



- Standard version

- Materials:

Spine: aluminium (unpainted)

Bristles: Specially woven steel

Woven steel
bristles

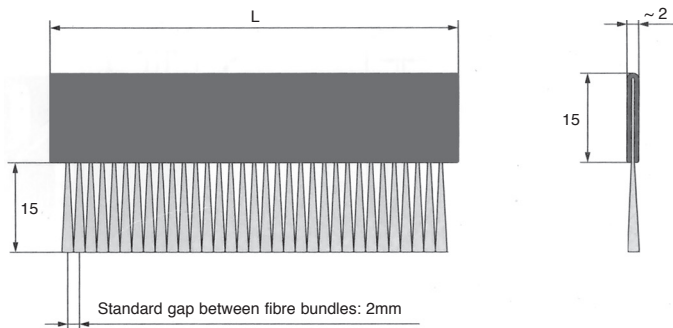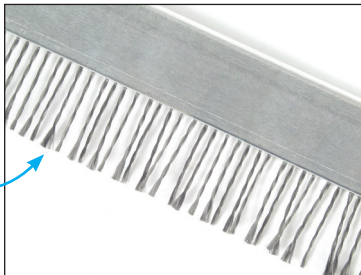

DISCOUNTS

Qty	1+	4+	6+	10+
Disc.	List	-10%	-15%	On request

Part number	Length L (mm)	Fibre material	Fibre Ø (mm)	Stock*	Price each 1 to 3
ABL100005-K1	1000	Steel	0,012	✓	48,98 €

*Depending on availability - Dimensions in mm

HPC

WEB
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

Our other products



VTHbr

Hexagonal headed screw VTH - DIN933, Brass



APB_BOU

Protective cap, Safety cap



 
CLLCLLP

Clevis components, long version, Steel - long version



PDD

Actuating plunger, Non-rotating detector shaft



PF55

Worm and wheel gear reducer, up to 57 Nm



DOMI50

Accessories, Turntable



H0

Crossed helical gear crossed axis at 90°, Steel 20NCD2



RTTss

Locking assembly, Medium/high torque



CHML40

Worm and wheel gear reducer, up to 57 Nm



D19_D29

Compression springs in metre length



BPHT

Ball transfer unit bolt fitting, Heavy



UGH25

H Type Guide units, For Ø25 actuators

Complementary products



ABL100000

Antistatic brush, For sensitive surfaces