

Antistatic brush



ABL With specially woven steel bristles

 


- Standard version

- Materials:

Spine: aluminium (unpainted)

Bristles: Specially woven steel

Woven steel
bristles

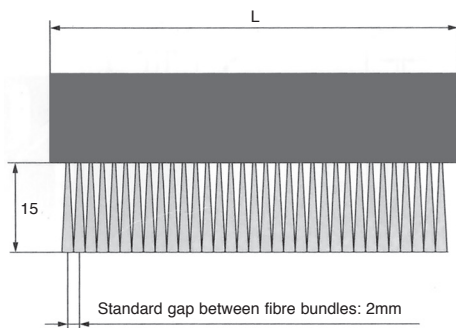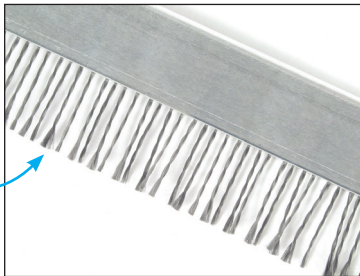

DISCOUNTS

Qty	1+	4+	6+	10+
Disc.	List	-10%	-15%	On request

Part number	Length L (mm)	Fibre material	Fibre Ø (mm)	Stock*	Price each 1 to 3
ABL100005-K1	1000	Steel	0,012	✓	48,98 €

*Depending on availability - Dimensions in mm

Our other products



AT5courroie

AT type timing belt,
AT5 Steel cored
polyurethane



DOG319

Motor-gearbox 12V
and 24V DC, from 4 to
9 Nm



 
SBF

Sealed flange bearing
unit for Food Industry,
cover




D19 D29

Compression springs
in metre length
stainless steel, by the
metre



PRF-SCREEN-1

 Screen support, Basic
support



PRF_TOOL

Assembly key for
aluminium profile,
Assembly key



DIV

Locking bolt, With grip
- Steel



CHAL3

Piano hinge, Steel



CHTRP

Single and dual
output gearboxes, Up
to 75,7 Nm



G2

Steel spur gear, Steel
20NCD2



NT121

Spur gear coaxial
gearbox, from 20 to
68 Nm - Inline



BOXsap

Boxed set of spring
pins ISO8752, Boxed
set - Split ISO 8752

Complementary products



ABL100000

Antistatic brush, For
sensitive surfaces