

Antistatic brush

Stock

ABL With specially woven steel bristles



- Standard version

- Materials:

Spine: aluminium (unpainted)

Bristles: Specially woven steel

Woven steel
bristles

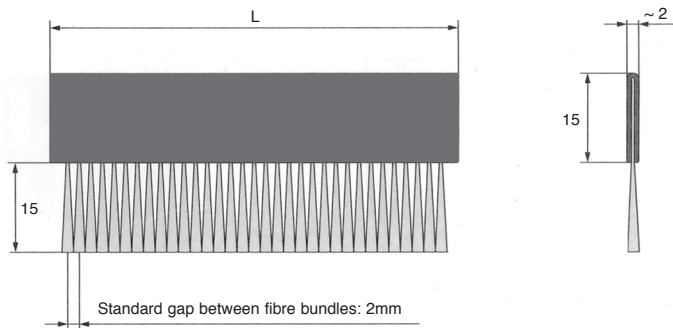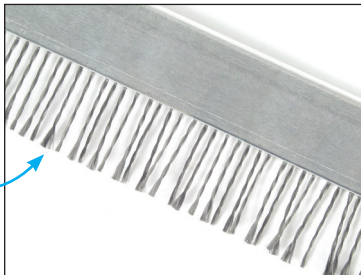

DISCOUNTS

Qty	1+	4+	6+	10+
Disc.	List -10%	-15%	On request	On request

Part number	Length L (mm)	Fibre material	Fibre Ø (mm)	Stock*	Price each 1 to 3
ABL100005-K1	1000	Steel	0,012	✓	48,98 €

*Depending on availability - Dimensions in mm

HPC

WEB
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

Our other products



QTR

Tapered roller bearing, Steel



ACLEPP

Right angled bracket for aluminium profile, 4 holes



RBGpl

Fixed castor with plate, Steel - grey rubber



BPHF

Ball transfer unit push fit, Heavy



BAC105

Storage bin, 8mm



RFV40

Stainless steel worm and wheel gearbox, up to 47 Nm



ERF

Quick fitting threaded cable terminal, Cable terminal with threaded ...



VELprf

Clip-on base for hook-and-loop strip, Polyamide



SER69K-CLE

Quarter turn latch for the food industry, Stainless steel key



T5-16ECO

T type timing pulley, Economy range - T5 aluminium



CLB_M

Die cast zinc clamping lever - female, Zamak



LRX

Linear roller slide, Chariot - from 9410 N to 101000 N

Complementary products



ABL100000

Antistatic brush, For sensitive surfaces