

Antistatic brush

Stock

ABL With specially woven steel bristles


- Standard version

- Materials:

Spine: aluminium (unpainted)

Bristles: Specially woven steel

Woven steel
bristles

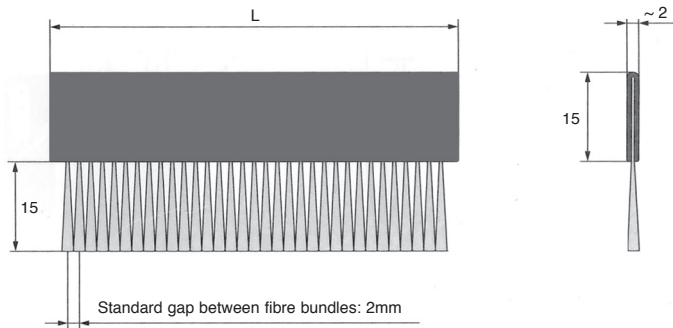

DISCOUNTS

Qty	1+	4+	6+	10+
Disc.	List -10%	-15%	On request	On request

Part number	Length L (mm)	Fibre material	Fibre Ø (mm)	Stock*	Price each 1 to 3
ABL100005-K1	1000	Steel	0,012	✓	48,98 €

*Depending on availability - Dimensions in mm

HPC

WEB
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

Our other products



BLHM40

Right angled gearbox, double output shafts, up to 10.3 Nm



M

Bellows cover, Accessory:



SLBW

Indexing plunger, weldable, Weldable - Steel




BEAS

Knob star grip antistatic, Star, anti-static



LBE

Miniature closed linear bearing, Miniature

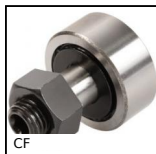

CF

Cam follower, Standard - steel



YGO

HEAVY DUTY spur gear, Steel 35NCD6




RVM25

Manually operated gearbox, Bevel



AT5-BAR

 AT type tooth bar stock, AT5



PO

Pull handle - Multi-sector, Smooth hole



CHAE6555

Decorative screwed hinge, Aluminium



SLVHlok

Vertical toggle clamp, Vertical toggle clamp / horizontal foot

Complementary products



ABL100000

Antistatic brush, For sensitive surfaces