

Hook for latch

Stock **Sta** **Ste**

ACZB
ACss

15mm wide versions

- Hook fastening
- Material: White zinc steel or stainless steel 303





Selection

- Choose your own hook/latch combination by simply verifying the interior width of the ring and selecting a hook with a smaller width

Info.

- Not sold individually, please contact us for details

steel or stainless steel

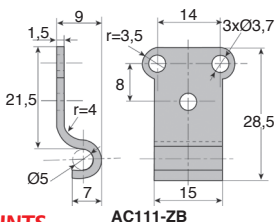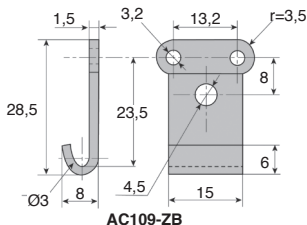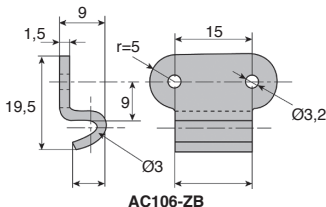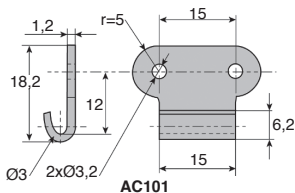

DISCOUNTS

Qty	1+	51+	101+	250+	400+	500+
Disc.	List	-10%	-15%	-20%	-25%	On request

Part number	Suitable for latch	Weight (g)	Stock*	Price each 1 to 50
Steel				
AC101-ZB	GE14-ZB	4,7	✓	0,59 €
AC106-ZB	GE14-ZB	5,2	✓	0,95 €
AC109-ZB	GE14-ZB	6,2	✓	0,82 €
AC111-ZB	GE14-ZB	6,8	✓	1,28 €
Stainless steel				
AC101-SS	GE1006-SS	4,7	✓	0,59 €

*Subject to availability - Dimensions in mm

Widths: 12, 13, 18 and 20mm

ACZB
ACSS

- Hook fastening
- Material: White zinc steel or stainless steel 303





Selection

- Choose your own hook/latch combination by simply verifying the interior width of the ring and selecting a hook with a smaller width

Info.

- Not sold individually, please contact us for details

steel or stainless steel

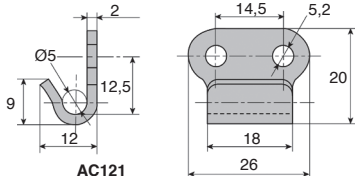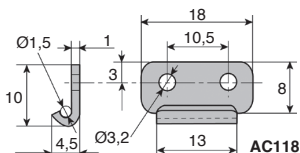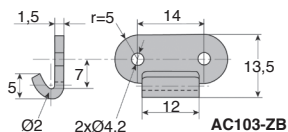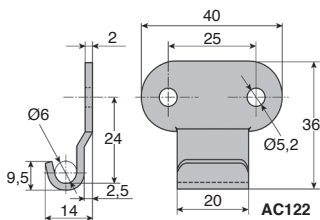

DISCOUNTS

Qty	1+	51+	101+	250+	400+	500+
Disc.	List	-10%	-15%	-20%	-25%	On request

Part number	Suitable for latch	Weight (g)	Stock*	Price each 1 to 50
Steel				
AC103-ZB	-	3,4	-	0,27 €
AC118-ZB	GE18-ZB	1,5	✓	0,20 €
AC121-ZB	GE5-ZB	9,4	✓	0,44 €
AC122-ZB	GP22-ZB and GP23-ZB	1,9	✓	0,82 €
Stainless steel				
AC118-SS	GE18-SS	1,5	✓	0,37 €
AC121-SS	GE5-SS	9,4	✓	1,18 €
AC122-SS	GP22-SS and GP23-SS	1,9	✓	2,29 €

*Subject to availability - Dimensions in mm

Our other products



UCP_PBT
Stainless/Polymer
pillow block bearing,
Polymer and stainless
steel



G3
Steel spur gear, Steel
20NCD2



MBF
Threaded blocking
clamp, Threaded
locking clamp



BLHB30
Right angled gearbox,
bored shafts, up to
4.47 Nm




SHA_PT
Handwheel with
handle, Polyamide



OP3
Mechanical digital
position indicator, 4
numbers



MCL
Reducing sleeve
female/female,
Cylindrical - stainless
steel

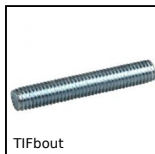

TIFbout
Threaded stud -
DIN976A, Steel



UTKswcr
Utilitrak® 3 wheels
carriage, Steel roller
carriage



SME
Male rod ends ,
Stainless steel / PTFE




CHAR6035
Spring hinge,
screwed/welded



ACLEFS
Floor anchor for
aluminium profile,
Standard

 Complementary products



GE
Toggle latches,
Standard



AC144
Strike for toggle latch,
22mm



AC156-157
Strike for toggle latch,
25.5mm



AC156-157
Strike for toggle latch,
25.5mm