



Widths: 12, 13, 18 and 20mm

ACZB  
ACSS

- Hook fastening
- Material: White zinc steel or stainless steel 303





## Selection

- Choose your own hook/latch combination by simply verifying the interior width of the ring and selecting a hook with a smaller width

## Info.

- Not sold individually, please contact us for details

steel or stainless steel

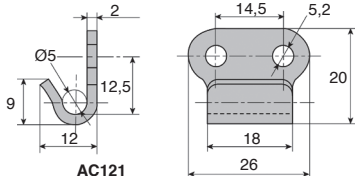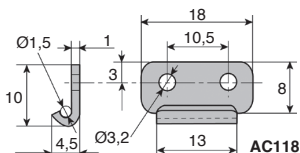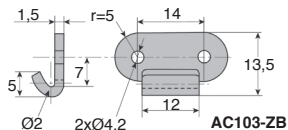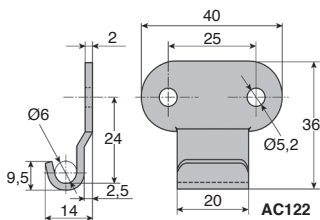

## DISCOUNTS

Qty	1+	51+	101+	250+	400+	500+
Disc.	List	-10%	-15%	-20%	-25%	On request

Part number	Suitable for latch	Weight (g)	Stock*	Price each 1 to 50
<b>Steel</b>				
AC103-ZB	-	3,4	-	0,27 €
AC118-ZB	GE18-ZB	1,5	✓	0,20 €
AC121-ZB	GE5-ZB	9,4	✓	0,44 €
AC122-ZB	GP22-ZB and GP23-ZB	1,9	✓	0,82 €
<b>Stainless steel</b>				
AC118-SS	GE18-SS	1,5	✓	0,37 €
AC121-SS	GE5-SS	9,4	✓	1,18 €
AC122-SS	GP22-SS and GP23-SS	1,9	✓	2,29 €

\*Subject to availability - Dimensions in mm

## Our other products




VTFL  
3 lobed handle,  
Polyamide - Brass



DIA  
Ring operated locking  
bolt, with ring



PSPE20  
Conical flexible shaft  
handle Ø20, Black  
PVC

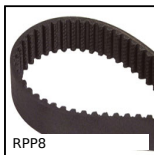

RPP8  
RPP heavy duty  
timing belt, RPP8



RFK38B  
Hypoid gearbox -  
Stainless steel, up to  
200 Nm



PRF\_SDD\_1820  
Support for Ø18 or  
Ø20mm Prox  
detector, Ø18 and  
Ø20



 
G01  
Single universal joint,  
Normal duty



CNA-CNG  
Right angled  
mounting plate, Right  
angled mounting  
plate for ball jo...



PLB  
Cylindrical spacer,  
Brass



B  
Steel bevel gear, 1:1



RFK48C  
Hypoid gearbox -  
Stainless steel, up to  
200 Nm



ES  
Support base (tripod),  
Plastic

## Complementary products



GE14  
Toggle latches, With  
padlock-holder