

Hook for latch

Stock **Sta** **Ste**

ACZB
ACss

15mm wide versions

- Hook fastening
- Material: White zinc steel or stainless steel 303





Selection

- Choose your own hook/latch combination by simply verifying the interior width of the ring and selecting a hook with a smaller width

Info.

- Not sold individually, please contact us for details

steel or
stainless steel

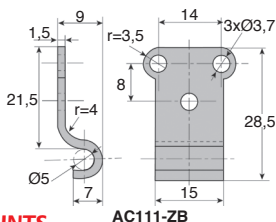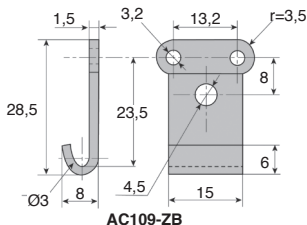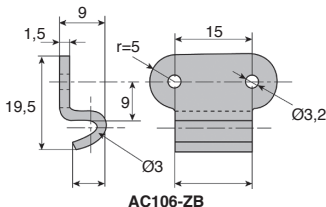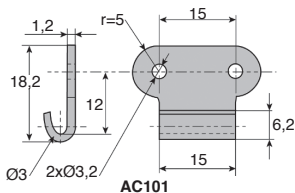

DISCOUNTS

Qty	1+	51+	101+	250+	400+	500+
Disc.	List	-10%	-15%	-20%	-25%	On request

Part number	Suitable for latch	Weight (g)	Stock*	Price each 1 to 50
Steel				
AC101-ZB	GE14-ZB	4,7	✓	0,59 €
AC106-ZB	GE14-ZB	5,2	✓	0,95 €
AC109-ZB	GE14-ZB	6,2	✓	0,82 €
AC111-ZB	GE14-ZB	6,8	✓	1,28 €
Stainless steel				
AC101-SS	GE1006-SS	4,7	✓	0,59 €

*Subject to availability - Dimensions in mm

Widths: 12, 13, 18 and 20mm

ACZB
ACSS

- Hook fastening
- Material: White zinc steel or stainless steel 303


Selection

- Choose your own hook/latch combination by simply verifying the interior width of the ring and selecting a hook with a smaller width

Info.

- Not sold individually, please contact us for details

steel or stainless steel

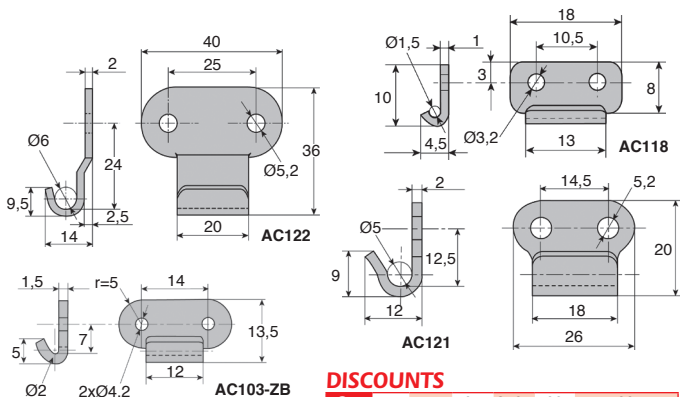


DISCOUNTS

Qty	1+	51+	101+	250+	400+	500+
Disc.	List	-10%	-15%	-20%	-25%	On request


Part number	Suitable for latch	Weight (g)	Stock*	Price each 1 to 50
Steel				
AC103-ZB	-	3,4	-	0,27 €
AC118-ZB	GE18-ZB	1,5	✓	0,20 €
AC121-ZB	GE5-ZB	9,4	✓	0,44 €
AC122-ZB	GP22-ZB and GP23-ZB	1,9	✓	0,82 €
Stainless steel				
AC118-SS	GE18-SS	1,5	✓	0,37 €
AC121-SS	GE5-SS	9,4	✓	1,18 €
AC122-SS	GP22-SS and GP23-SS	1,9	✓	2,29 €

*Subject to availability - Dimensions in mm

 
Our other products



 RPPM
RPP type belt per metre, RPP8 Steel cored polyurethane



 M1
Worm and wheel set, Machined plastic (delrin)



CFC
Spring loaded position switch, Electric contact



CHAE4080PA
Symmetrical decorative screwed hinge, Polyamide



T5P_T10P
Connecting plate for T type timing belts, T10



ACLBTs
Spherical ended stop for aluminium profile, Spherical ended stop



PFC
Fixed rubber levelling foot, Levelling support for small parts



PLA
Flat magnet, Flat magnet




BAC105
Storage bin, 8mm



J64
Spur gear coaxial gearbox, from 0.57 to 1.14



NPTF30
Fixed tube carrier, Fixed Ø14 to Ø20

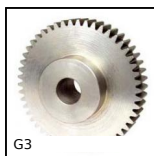

G3
Steel spur gear, Steel 20NCD2

Complementary products



GE14
Toggle latches, With padlock-holder