

Hook for latch

Stock **Sta** **Ste**

ACZB
ACss

15mm wide versions

- Hook fastening
- Material: White zinc steel or stainless steel 303





Selection

- Choose your own hook/latch combination by simply verifying the interior width of the ring and selecting a hook with a smaller width

Info.

- Not sold individually, please contact us for details

steel or
stainless steel

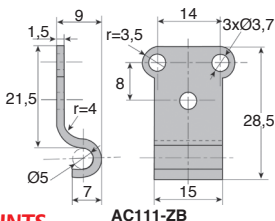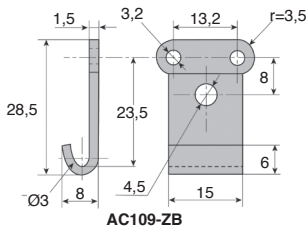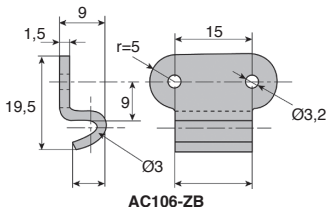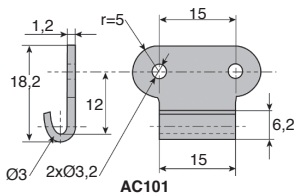

DISCOUNTS

Qty	1+	51+	101+	250+	400+	500+
Disc.	List	-10%	-15%	-20%	-25%	On request

Part number	Suitable for latch	Weight (g)	Stock*	Price each 1 to 50
Steel				
AC101-ZB	GE14-ZB	4,7	✓	0,59 €
AC106-ZB	GE14-ZB	5,2	✓	0,95 €
AC109-ZB	GE14-ZB	6,2	✓	0,82 €
AC111-ZB	GE14-ZB	6,8	✓	1,28 €
Stainless steel				
AC101-SS	GE1006-SS	4,7	✓	0,59 €

*Subject to availability - Dimensions in mm

Widths: 12, 13, 18 and 20mm

ACZB
ACSS

- Hook fastening
- Material: White zinc steel or stainless steel 303





Selection

- Choose your own hook/latch combination by simply verifying the interior width of the ring and selecting a hook with a smaller width

Info.

- Not sold individually, please contact us for details

steel or stainless steel

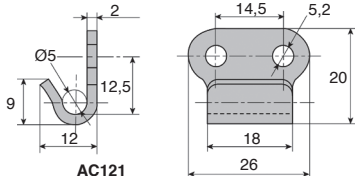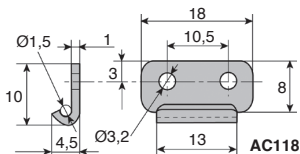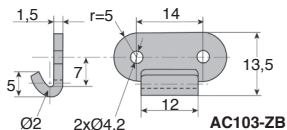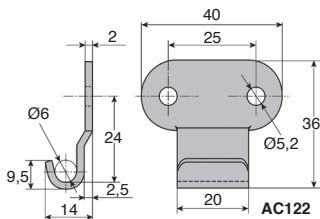

DISCOUNTS

Qty	1+	51+	101+	250+	400+	500+
Disc.	List	-10%	-15%	-20%	-25%	On request

Part number	Suitable for latch	Weight (g)	Stock*	Price each 1 to 50
Steel				
AC103-ZB	-	3,4	-	0,27 €
AC118-ZB	GE18-ZB	1,5	✓	0,20 €
AC121-ZB	GE5-ZB	9,4	✓	0,44 €
AC122-ZB	GP22-ZB and GP23-ZB	1,9	✓	0,82 €
Stainless steel				
AC118-SS	GE18-SS	1,5	✓	0,37 €
AC121-SS	GE5-SS	9,4	✓	1,18 €
AC122-SS	GP22-SS and GP23-SS	1,9	✓	2,29 €

*Subject to availability - Dimensions in mm

Our other products




BAGtr
Lead screw clamping collar, Aluminium



PT820
Drive sprocket for slat top chain, Ranges 820 and 815



CLAT
Clamping lever Hygienic Usit® - male, Stainless steel

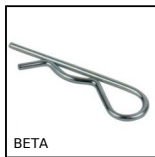


BETA
Hitch pin, Hitch



AT5M AT10M
AT type timing belt per metre, AT10 Steel cored polyurethane



GD01
Double universal joint, Standard duty

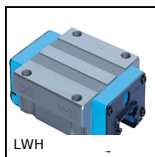

LWH
High rigidity linear slide, Chariot - from 9320 N to 71300 N



SLH
Horizontal toggle clamp, Horizontal Lever Clamp - steel



LRR22
Small dimension latch with locking system, Aluminium



BOX-TOR-D
Box set of Nitrile O-rings in nitrile, 18.00 x 2.00mm to 50.00 x



GLP
Small 6 lobe threaded handle - male, Technopolymer - Steel



CFF
Female rod ends DIN ISO12240-4, Steel / bronze

Complementary products



GP
Spring loaded toggle latch, Standard



GP
Spring loaded toggle latch, With padlock-holder