

# Hook for latch

Stock **Sta** **Ste**

ACZB  
ACss

15mm wide versions

- Hook fastening
- Material: White zinc steel or stainless steel 303


## Selection

- Choose your own hook/latch combination by simply verifying the interior width of the ring and selecting a hook with a smaller width


## Info.

- Not sold individually, please contact us for details


steel or stainless steel

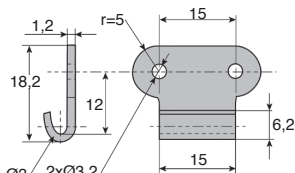


AC101

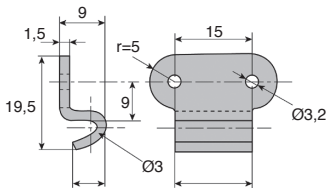

AC106-ZB

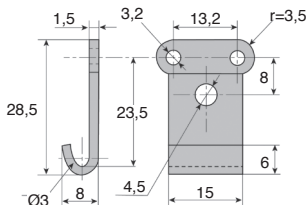

AC109-ZB

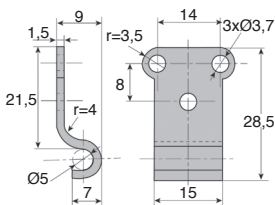

AC111-ZB

## DISCOUNTS

Qty	1+	51+	101+	250+	400+	500+
Disc.	List	-10%	-15%	-20%	-25%	On request

Part number	Suitable for latch	Weight (g)	Stock*	Price each 1 to 50
<b>Steel</b>				
AC101-ZB	GE14-ZB	4,7	✓	0,59 €
AC106-ZB	GE14-ZB	5,2	✓	0,95 €
AC109-ZB	GE14-ZB	6,2	✓	0,82 €
AC111-ZB	GE14-ZB	6,8	✓	1,28 €
<b>Stainless steel</b>				
AC101-SS	GE1006-SS	4,7	✓	0,59 €

\*Subject to availability - Dimensions in mm

HPC

WEB  
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15€/min + prix appel

Widths: 12, 13, 18 and 20mm

ACZB  
ACSS

- Hook fastening
- Material: White zinc steel or stainless steel 303


## Selection

- Choose your own hook/latch combination by simply verifying the interior width of the ring and selecting a hook with a smaller width

## Info.

- Not sold individually, please contact us for details

steel or stainless steel

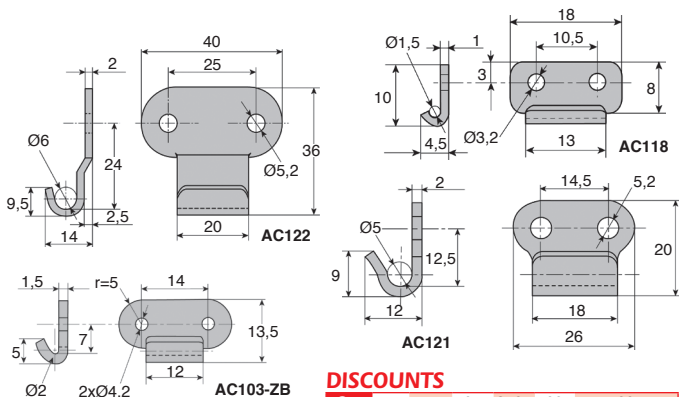

## DISCOUNTS

Qty	1+	51+	101+	250+	400+	500+
Disc.	List	-10%	-15%	-20%	-25%	On request

Part number	Suitable for latch	Weight (g)	Stock*	Price each 1 to 50
<b>Steel</b>				
AC103-ZB	-	3,4	-	0,27 €
AC118-ZB	GE18-ZB	1,5	✓	0,20 €
AC121-ZB	GE5-ZB	9,4	✓	0,44 €
AC122-ZB	GP22-ZB and GP23-ZB	1,9	✓	0,82 €
<b>Stainless steel</b>				
AC118-SS	GE18-SS	1,5	✓	0,37 €
AC121-SS	GE5-SS	9,4	✓	1,18 €
AC122-SS	GP22-SS and GP23-SS	1,9	✓	2,29 €

\*Subject to availability - Dimensions in mm

## Our other products



ACM\_AZ  
Mounting bracket for bonnet fastener, Hook



BPPEBLU  
Ball transfer unit in blue certified plastic, for foodstuff sector



KB\_UU  
Closed linear precision bearing, Precision - steel



CCL  
Standard wire thimble, Steel



WFRM  
Flanged polymer nut, Polymer (Iglidur®) - 1 thread



DOMI80  
Connecting kits, XZ linking kit



ESCON  
Speed controller 5A accessories, USB cable for PC link



GET-AL  
Jaw coupling, economy range, Aluminium



CDC  
Conical compression spring, Conical



DOMI80  
Domino 80 adjustable slide, Slide DOMILINE



YG0  
HEAVY DUTY spur gear, Steel 35NCD6



DBL805  
Idler for slat top chain, Range 805

## Complementary products



GE  
Toggle latches, Standard



AC144  
Strike for toggle latch, 22mm



AC156-157  
Strike for toggle latch, 25.5mm



AC156-157  
Strike for toggle latch, 25.5mm