

Hook for latch



ACZB ACss

15mm wide versions

- Hook fastening
- Material: White zinc steel or stainless steel 303





Selection

- Choose your own hook/latch combination by simply verifying the interior width of the ring and selecting a hook with a smaller width

Info.

- Not sold individually, please contact us for details

steel or
stainless steel

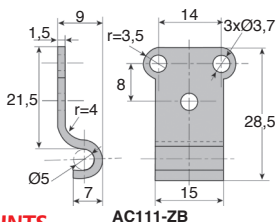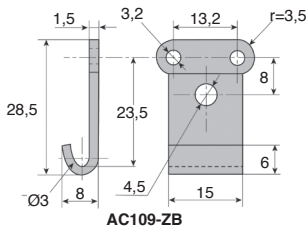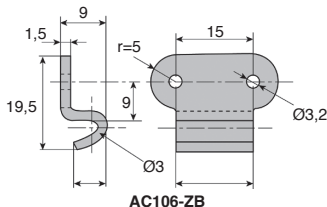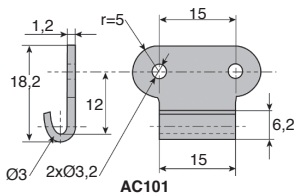

DISCOUNTS

Qty	1+	51+	101+	250+	400+	500+
Disc.	List	-10%	-15%	-20%	-25%	On request

Part number	Suitable for latch	Weight (g)	Stock*	Price each 1 to 50
Steel				
AC101-ZB	GE14-ZB	4,7	✓	0,59 €
AC106-ZB	GE14-ZB	5,2	✓	0,95 €
AC109-ZB	GE14-ZB	6,2	✓	0,82 €
AC111-ZB	GE14-ZB	6,8	✓	1,28 €
Stainless steel				
AC101-SS	GE1006-SS	4,7	✓	0,59 €

*Subject to availability - Dimensions in mm

HPC

WEB
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

Widths: 12, 13, 18 and 20mm

ACZB
ACSS

- Hook fastening
- Material: White zinc steel or stainless steel 303





Selection

- Choose your own hook/latch combination by simply verifying the interior width of the ring and selecting a hook with a smaller width

Info.

- Not sold individually, please contact us for details

steel or stainless steel

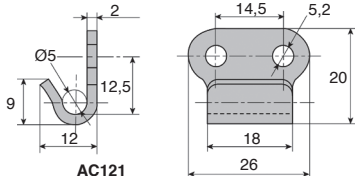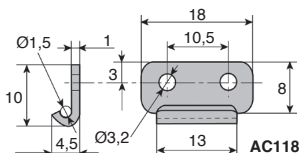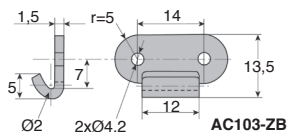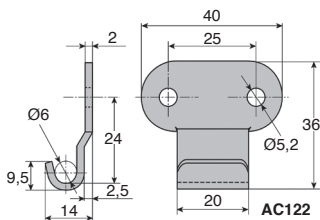


DISCOUNTS

Qty	1+	51+	101+	250+	400+	500+
Disc.	List	-10%	-15%	-20%	-25%	On request

Part number	Suitable for latch	Weight (g)	Stock*	Price each 1 to 50
Steel				
AC103-ZB	-	3,4	-	0,27 €
AC118-ZB	GE18-ZB	1,5	✓	0,20 €
AC121-ZB	GE5-ZB	9,4	✓	0,44 €
AC122-ZB	GP22-ZB and GP23-ZB	1,9	✓	0,82 €
Stainless steel				
AC118-SS	GE18-SS	1,5	✓	0,37 €
AC121-SS	GE5-SS	9,4	✓	1,18 €
AC122-SS	GP22-SS and GP23-SS	1,9	✓	2,29 €


*Subject to availability - Dimensions in mm

 Our other products



LAT4

 4A motorised linear actuator, 4 amperes



BMF

Knurled knob - female, Knurled - through threaded



SHNbr

Hexagonal nut DIN934, Brass



 
PGB

Accessory-holder for aluminium profile, Tool holder



AC

Strike for toggle latch, 12mm



BLHM20

Right angled gearbox, double output shafts, up to 1.77 Nm



GLT3-46A

Telescopic drawer with damper,



PRF_CH

Cable-carrier chain for aluminium profile, Supplied in metre lengths



TFR

Rigid manual tensioner, Fixed



BABFCFO

Ball pin socket, Mounting collar with a



INS_BR

Self tapping brass insert, Brass



PGM86-M5

Pull handle, Thermoplastic

Complementary products



GE14

Toggle latches, With padlock-holder