

# Hook for latch

Stock **Sta** **Ste**

ACZB  
ACss

15mm wide versions

- Hook fastening
- Material: White zinc steel or stainless steel 303





## Selection

- Choose your own hook/latch combination by simply verifying the interior width of the ring and selecting a hook with a smaller width

## Info.

- Not sold individually, please contact us for details

steel or stainless steel

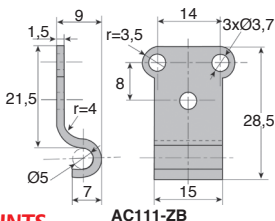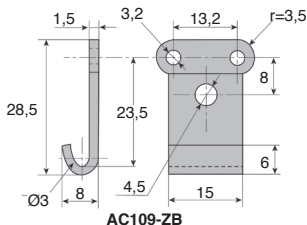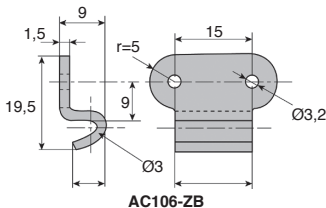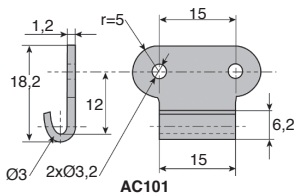

## DISCOUNTS

Qty	1+	51+	101+	250+	400+	500+
Disc.	List	-10%	-15%	-20%	-25%	On request

Part number	Suitable for latch	Weight (g)	Stock*	Price each 1 to 50
<b>Steel</b>				
AC101-ZB	GE14-ZB	4,7	✓	0,59 €
AC106-ZB	GE14-ZB	5,2	✓	0,95 €
AC109-ZB	GE14-ZB	6,2	✓	0,82 €
AC111-ZB	GE14-ZB	6,8	✓	1,28 €
<b>Stainless steel</b>				
AC101-SS	GE1006-SS	4,7	✓	0,59 €

\*Subject to availability - Dimensions in mm

HPC

WEB  
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

Widths: 12, 13, 18 and 20mm

ACZB  
ACSS

- Hook fastening
- Material: White zinc steel or stainless steel 303


## Selection

- Choose your own hook/latch combination by simply verifying the interior width of the ring and selecting a hook with a smaller width

## Info.

- Not sold individually, please contact us for details

steel or stainless steel

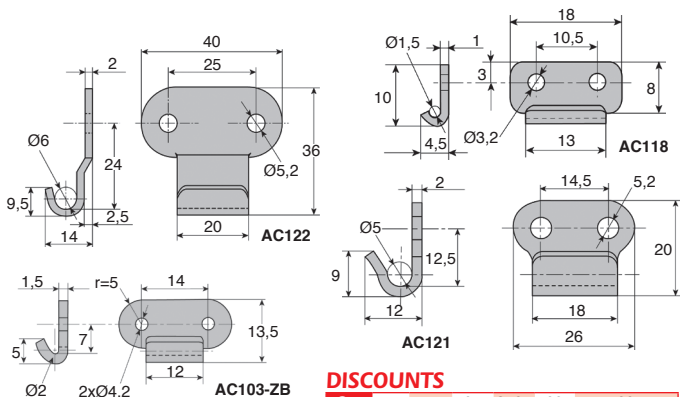

## DISCOUNTS

Qty	1+	51+	101+	250+	400+	500+
Disc.	List	-10%	-15%	-20%	-25%	On request

Part number	Suitable for latch	Weight (g)	Stock*	Price each 1 to 50
<b>Steel</b>				
AC103-ZB	-	3,4	-	0,27 €
AC118-ZB	GE18-ZB	1,5	✓	0,20 €
AC121-ZB	GE5-ZB	9,4	✓	0,44 €
AC122-ZB	GP22-ZB and GP23-ZB	1,9	✓	0,82 €
<b>Stainless steel</b>				
AC118-SS	GE18-SS	1,5	✓	0,37 €
AC121-SS	GE5-SS	9,4	✓	1,18 €
AC122-SS	GP22-SS and GP23-SS	1,9	✓	2,29 €

\*Subject to availability - Dimensions in mm

 
## Our other products



GE\_ET\_2RS  
Spherical bushing,  
Hard chromium /  
Teflon contact with  
seals



PRF\_JL5  
Lip seal for panel,  
Door seal - Ø 5mm



MR\_MMR  
Metric section rack,  
Steel



CHNrb  
Warning chain with  
red and white links,  
Steel



RFK48C  
Hypoid gearbox -  
Stainless steel, up to  
350 Nm



PCLA\_M  
Technopolymer  
clamping lever -  
female, Plastic



HTD5M\_25  
HTD Heavy duty  
timing pulley, HTD5  
Steel



M1  
Worm and wheel set,  
Non hardened steel



NRV  
Orthogonal support  
clamp, Orthogonal  
support clamp



NDS20  
Double cross clamp,  
Crossed



GFX  
Curved tooth  
coupling, economy  
range, Steel and



PO  
Pull handle - Multi-  
sector, Tapped  
recessed insert

## Complementary products



GE  
Toggle latches,  
Miniature