

Hook for latch

Stock **Sta** **Ste**

ACZB
ACss

15mm wide versions

- Hook fastening
- Material: White zinc steel or stainless steel 303


Selection

- Choose your own hook/latch combination by simply verifying the interior width of the ring and selecting a hook with a smaller width


Info.

- Not sold individually, please contact us for details


steel or stainless steel

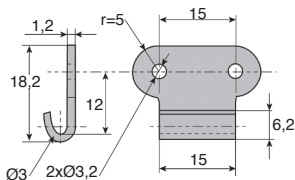


AC101

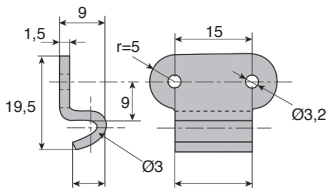

AC106-ZB

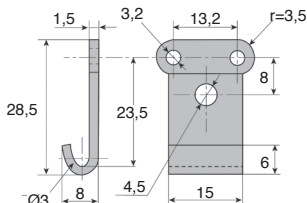

AC109-ZB

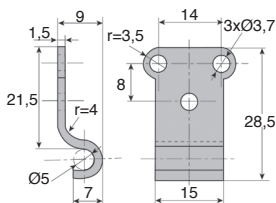

AC111-ZB

DISCOUNTS

Qty	1+	51+	101+	250+	400+	500+
Disc.	List	-10%	-15%	-20%	-25%	On request

Part number	Suitable for latch	Weight (g)	Stock*	Price each 1 to 50
Steel				
AC101-ZB	GE14-ZB	4,7	✓	0,59 €
AC106-ZB	GE14-ZB	5,2	✓	0,95 €
AC109-ZB	GE14-ZB	6,2	✓	0,82 €
AC111-ZB	GE14-ZB	6,8	✓	1,28 €
Stainless steel				
AC101-SS	GE1006-SS	4,7	✓	0,59 €

*Subject to availability - Dimensions in mm

Widths: 12, 13, 18 and 20mm

ACZB
ACSS

- Hook fastening
- Material: White zinc steel or stainless steel 303


Selection

- Choose your own hook/latch combination by simply verifying the interior width of the ring and selecting a hook with a smaller width

Info.

- Not sold individually, please contact us for details

steel or stainless steel

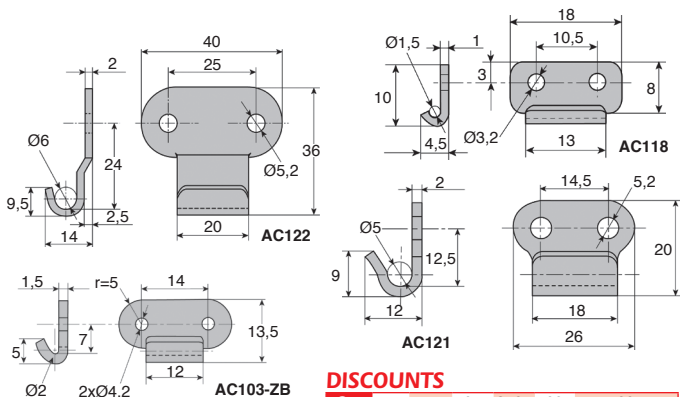

DISCOUNTS

Qty	1+	51+	101+	250+	400+	500+
Disc.	List	-10%	-15%	-20%	-25%	On request

Part number	Suitable for latch	Weight (g)	Stock*	Price each 1 to 50
Steel				
AC103-ZB	-	3,4	-	0,27 €
AC118-ZB	GE18-ZB	1,5	✓	0,20 €
AC121-ZB	GE5-ZB	9,4	✓	0,44 €
AC122-ZB	GP22-ZB and GP23-ZB	1,9	✓	0,82 €
Stainless steel				
AC118-SS	GE18-SS	1,5	✓	0,37 €
AC121-SS	GE5-SS	9,4	✓	1,18 €
AC122-SS	GP22-SS and GP23-SS	1,9	✓	2,29 €

*Subject to availability - Dimensions in mm

Our other products



MSP19

Masterplate® glueable insert Ø19, Cylindrical with tapped insert



PCS75K

Chain sprocket with hardened teeth, 19.05mm (DIN12B-1)



PMC48_M8

Anti-vibration machine mount, Oval base plate



PTAF100-PAMF100

Articulated fixable foot with pressed base Ø100, Ø 100



RAGFLOW

Floway2® roller track, Roller track



LSAG

Precision linear rotary ball spline, Rail - from 514 N to 15386 N



VCMB

Dual-thread screw wood/metal, Stainless steel



ACL-PLAngle

Joining plate for aluminium profile, Angle connection



BAG0

Locking rings in steel, Steel



PM3

Worm and wheel set, Non hardened steel



PRF_PL_4590

Joining plate for aluminium profile, Joint plate - 45x90



NAST

Cam follower without axial guide, With interior ring

Complementary products



GE

Toggle latches, Miniature