


- Closed by latching
- Materials:  
White zinc plated steel  
18/8 stainless steel, natural finish

**Accessory**

- GP75-ZB and GP75-SS toggle latches



Steel or  
stainless steel

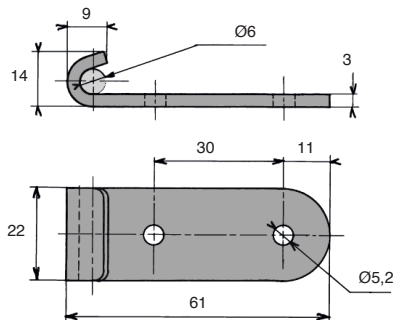**DISCOUNTS**

Qty	1+	51+	101+	250+	400+
Disc.	List	-10%	-15%	-20%	On request

Part N°	Material	Suitable for latch	Weight (g)	Stock*	Price each 1 to 50
<b>Flat</b>					
AC144-ZB	Steel	GP75-ZB	35	-	0,86 €
AC144-SS	Stainless steel	GP75-SS	35	✓	2,74 €

All dimensions in mm

## Our other products



CAP882  
Flexible slat top chain  
acetal, Large range  
882



PLM-C  
Cylindrical holding  
magnets, Cylindrical  
holding magnet



 
HCSS  
Set screw with  
hexagonal socket,  
Cup point



RJUM05  
Drylin R® linear  
bearing housing,  
Closed - Long



CHAEpac  
Square decorative  
screwed hinges,  
carbon fibre  
reinforced



T5courroie  
T type timing belt, T5  
Steel cored  
polyurethane



AC156-157  
Strike for toggle latch,  
25.5mm



S4  
Chain sprocket-  
stainless steel, 4mm



PTMR  
Telescopic furniture  
foot, threaded stud



ACLERP  
Roller block for  
aluminium profile,  
Without guide rail



BFA  
Shaft locking washer,  
E clip



HTD5M\_15  
HTD Heavy duty  
timing pulley, HTD5  
Steel

## Complementary products



GP75  
Spring loaded toggle  
latch, Standard  
(GP75)



AC  
Strike for toggle latch,  
15mm



AC  
Strike for toggle latch,  
12, 13, 18 and 20mm