


- Closed by latching
- Materials:
White zinc plated steel
18/8 stainless steel, natural finish

Accessory

- GP75-ZB and GP75-SS toggle latches

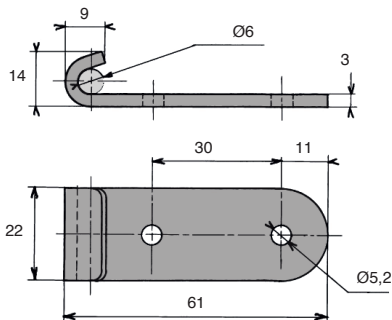

DISCOUNTS

Qty	1+	51+	101+	250+	400+
Disc.	List	-10%	-15%	-20%	On request

Part N°	Material	Suitable for latch	Weight (g)	Stock*	Price each 1 to 50
Flat					
AC144-ZB	Steel	GP75-ZB	35	-	0,86 €
AC144-SS	Stainless steel	GP75-SS	35	✓	2,74 €

All dimensions in mm

Our other products



PRF_BASE
Base plate for
aluminium profile,
Base plate



SCA
Flat cable clamp,
Steel



VRC1
Retaining clamp,
single sided, Single
sided




Q6
Deep groove ball
bearing, Steel



PT821
Drive sprocket for
slat top chain, Ranges
821 and 805



CHML63
Worm and wheel gear
reducer, up to 138
Nm - Integrated
torque limiter

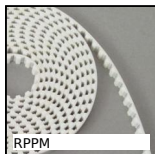


RPPM
RPP type belt per
metre, RPP8 Steel
cored polyurethane



CHAFR-MINI
Miniature friction
hinge, Friction



 
PPF
Indexing plunger with
flange, with drilled



PF45
Worm and wheel gear
reducer, up to 40 Nm



TIF
Threaded rod -
DIN975, Stainless

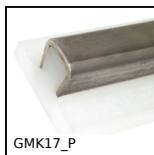

GMK17_P
Flat Guide, Flat guide
for conical profile

Complementary products



GP75
Spring loaded toggle
latch, Standard
(GP75)