


- Closed by latching
- Materials:  
White zinc plated steel  
18/8 stainless steel, natural finish

### Accessory

- GP75-ZB and GP75-SS toggle latches

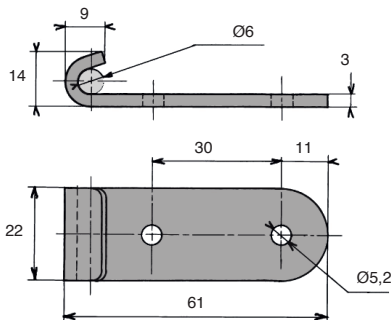

### DISCOUNTS

Qty	1+	51+	101+	250+	400+
Disc.	List	-10%	-15%	-20%	On request

Part N°	Material	Suitable for latch	Weight (g)	Stock*	Price each 1 to 50
<b>Flat</b>					
AC144-ZB	Steel	GP75-ZB	35	-	0,86 €
AC144-SS	Stainless steel	GP75-SS	35	✓	2,74 €

All dimensions in mm

## Our other products



PM4  
Worm and wheel set,  
Hardened steel



UGH16  
H Type Guide units,  
For  $\varnothing 12$  and  $\varnothing 16$   
actuators



712\_001  
Ball knob, spherical



HLC24  
Right angle spiro  
bevel gearbox, Up to  
78Nm



CHINV  
Invisible hinge,  
Invisible - 90° opening



KKB-AR  
Linear bearing with  
inclined ball tracks,  
Standard loads / -20°  
+20...



 
PRT-TO  
iglidur® slewing ring,  
With external teeth-  
Iglidur®, aluminium &  
S...



PLS  
Cylindrical spacer,  
Stainless steel 303



CHAC4040SS  
Square hinge with  
riveted pin, drilled,  
Square with riveted



B  
Steel bevel gear, 1:1



RTK  
BoWex® curved tooth  
gear coupling, Nylon  
and steel



CHA225  
Screwed hinge with  
threaded insert, 225  
degrees

## Complementary products



GP75  
Spring loaded toggle  
latch, Standard  
(GP75)