

25.5mm wide version

AC156  
AC157



## - Closed by latching

## - Materials:

White zinc plated steel  
18/8 stainless steel, natural finish

## Accessories

- GP75-ZB and GP75-SS toggle latches

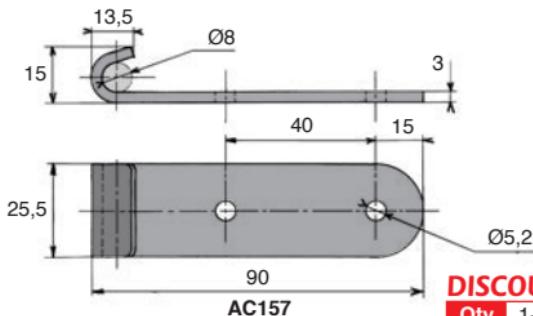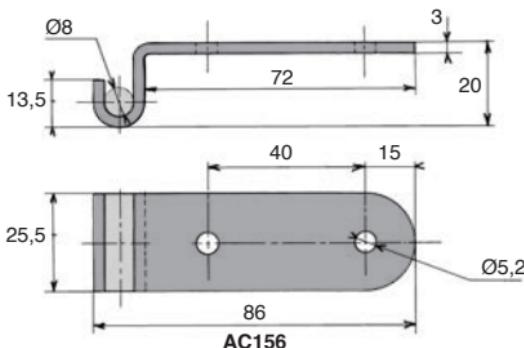

## DISCOUNTS

Qty	1+	51+	101+	250+	400+
Disc.	List	-10%	-15%	-20%	On request

Part N°	Material	Suitable for latch	Weight (g)	Stock*	Price each 1 to 49
<b>Right angled</b>					
AC156-ZB	Steel	GE32-ZB	59	-	0,88 €
AC156-SS	Stainless steel	GE32-SS	59	✓	4,04 €
<b>Flat</b>					
AC157-ZB	Steel	GE32-ZB	59	✓	0,88 €
AC157-SS	Stainless steel	GE32-SS	59	-	4,04 €

All dimensions in mm

Fax

0 825 88 6000

Service 0,15 € / min  
+ prix appel

cial2@hpceurope.com

HPC

SUPPLEMENT 2019

169

## Our other products



TPEF

Castor for aluminium profile, Fixed



CSSSS

Stainless steel spherical bearing, Stainless steel / PTFE



KB\_WW

Closed linear precision bearing, Economy range



H0

Crossed helical gear crossed axis at 90°, Steel 20NCD2



DOMI80

Connecting kits, XZ linking kit



P55

Worm and wheel gear reducer, up to 57 Nm



PMC48\_M8

Anti-vibration machine mount, Oval base plate



SUPCC

Self-centering clamping hub steel, With lock nut



PRF-SRA-78

Lock for aluminium profile, Quick fitting, self locking door lock



ARTE

Flexible bush, For multi-directional loads



CLG1

Moulded plastic spur gear, Moulded plastic (nylon)



PSG05S

Spur gear - precision range, Stainless steel 303

## Complementary products



GE32

Sprung toggle latch with connecting link, Standard



Strike for toggle latch, 25.5mm



AC156-157

Strike for toggle latch, 25.5mm



AC

Strike for toggle latch, 15mm