
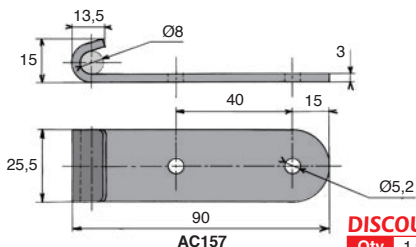


- Closed by latching
- Materials:
White zinc plated steel
18/8 stainless steel, natural finish

Accessories

- GP75-ZB and GP75-SS toggle latches

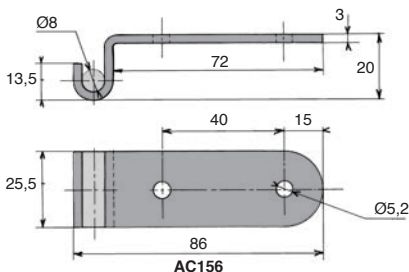

DISCOUNTS

| | | | | | |
|-------|------|------|------|------|------------|
| Qty | 1+ | 51+ | 101+ | 250+ | 400+ |
| Disc. | List | -10% | -15% | -20% | On request |

| Part N° | Material | Suitable for latch | Weight (g) | Stock* | Price each 1 to 49 |
|---------------------|-----------------|--------------------|------------|--------|--------------------|
| Right angled | | | | | |
| AC156-ZB | Steel | GE32-ZB | 59 | - | 0,88 € |
| AC156-SS | Stainless steel | GE32-SS | 59 | ✓ | 4,04 € |
| Flat | | | | | |
| AC157-ZB | Steel | GE32-ZB | 59 | ✓ | 0,88 € |
| AC157-SS | Stainless steel | GE32-SS | 59 | - | 4,04 € |

All dimensions in mm

0 825 88 6000
Service 0,15 € / min
+ prix appel

Our other products



PRF-SCREEN-5
Screen support,
Support with 5 axes of
rotation



PRF_PGN
Door handle for
aluminium profile,
Handle with lock
suitable



BIMSS
Indexing plunger mini,
miniature - Stainless
steel



SSB
Stainless steel bevel
gear, 1:1



M0
Worm and wheel set,
Machined plastic
(delrin)



H4
Crossed helical gear
crossed axis at 90°,
Steel 20NCD2



SBRtool
Chain tool, Drive
chain maintenance
tools



VRC1
Retaining clamp,
single sided, Single
sided



BABPass
Hardened stainless
steel ball pin with
ring, With grip ring



gt64
Rotating bent lever,
Common applications



PRES
Manual workbench
press accessory for
PRES-3HR end



PTRSS
Idler chain sprocket,
For hostile
environments

Complementary products



GE32
Sprung toggle latch
with connecting link,
Standard



AC156-157
Strike for toggle latch,
25.5mm



AC
Strike for toggle latch,
15mm



AC
Strike for toggle latch,
12,13,18 and 20mm