
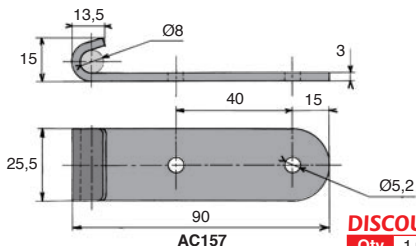


- Closed by latching
- Materials:
White zinc plated steel
18/8 stainless steel, natural finish

Accessories

- GP75-ZB and GP75-SS toggle latches

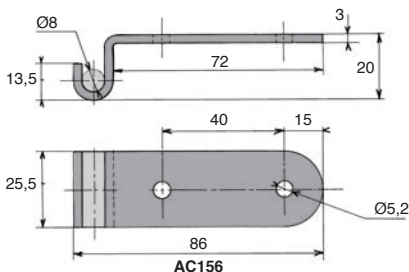

DISCOUNTS

Qty	1+	51+	101+	250+	400+
Disc.	List	-10%	-15%	-20%	On request

Part N°	Material	Suitable for latch	Weight (g)	Stock*	Price each 1 to 49
Right angled					
AC156-ZB	Steel	GE32-ZB	59	-	0,88 €
AC156-SS	Stainless steel	GE32-SS	59	✓	4,04 €
Flat					
AC157-ZB	Steel	GE32-ZB	59	✓	0,88 €
AC157-SS	Stainless steel	GE32-SS	59	-	4,04 €

All dimensions in mm

0 825 88 6000

Service 0,15 € / min
+ prix appel

Our other products



WJRM
Drylin® W hybrid bearing block, Hybrid bearings



SUA4_L
Chain link, Steel



BAG-MI
Split shaft collar with clamp lever, Steel



T5-16ECO
T type timing pulley, Economy range - T5 aluminium



DIL
Lever operated locking bolt, lever clamp



H2
Crossed helical gear crossed axis at 90°, Steel 20NCD2




MSP23
Masterplate® glueable insert Ø23, Cylindrical Ø23 with threaded s...



SSB
Stainless steel bevel gear, 1:1



 CABtool
Fitting cable tools, Crimping tools



STL
Guidance brush - Brush, Brush



NAST
Cam follower without axial guide, With interior ring



V3RA
3-spoked handwheel without handle, Polyamide

Complementary products



GE32
Sprung toggle latch with connecting link, Standard



AC156-157
Strike for toggle latch, 25.5mm



AC156-157
Strike for toggle latch, 25.5mm