
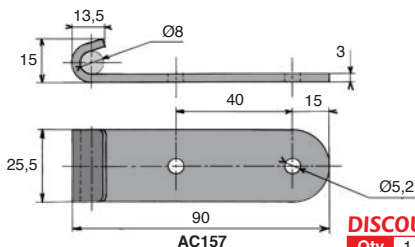


- Closed by latching
- Materials:
White zinc plated steel
18/8 stainless steel, natural finish

Accessories

- GP75-ZB and GP75-SS toggle latches

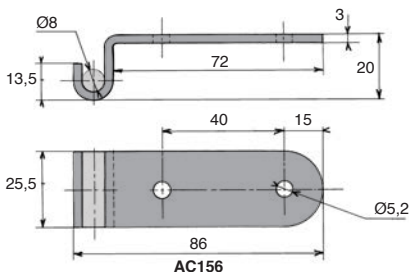

DISCOUNTS

Qty	1+	51+	101+	250+	400+
Disc.	List	-10%	-15%	-20%	On request

Part N°	Material	Suitable for latch	Weight (g)	Stock*	Price each 1 to 49
Right angled					
AC156-ZB	Steel	GE32-ZB	59	-	0,88 €
AC156-SS	Stainless steel	GE32-SS	59	✓	4,04 €
Flat					
AC157-ZB	Steel	GE32-ZB	59	✓	0,88 €
AC157-SS	Stainless steel	GE32-SS	59	-	4,04 €

All dimensions in mm

0 825 88 6000
Service 0,15 € / min
+ prix appel

Our other products



TRM

Spur round rack, Steel
- module 1-6



MDB_MTB

Moulded plastic bevel
gear (nylon), 3:1



PSG255

Spur gear - precision
range, Stainless steel
316



CHTRB

Single and dual
output gearboxes, Up
to 87,3 Nm



DOMI50

Accessories, Clamping
lever



NTM

Nylon tipped set
screw, Nylon-point



BPFss

Pressed stainless
steel flange bearing,
Stainless steel



PRF_PIV

Internal hinge pin for
aluminium profile,
Internal hinge pin



BPHRF

Ball transfer unit
housed spring loaded,
High



DCA

Suction cup, 1.5
bellows, natural
rubber



PRF-SCREEN-4

Screen support,
Support with 4 axes
of rotation



PTAF100-PAMF100

Articulated fixable
foot with pressed
base Ø100, Ø 100

Complementary products



GE32

Sprung toggle latch
with connecting link,
Standard



AC156-157

Strike for toggle latch,
25.5mm



AC156-157

Strike for toggle latch,
25.5mm