
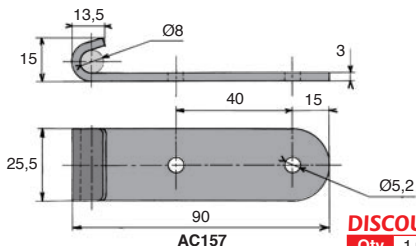


- Closed by latching
- Materials:  
White zinc plated steel  
18/8 stainless steel, natural finish

### Accessories

- GP75-ZB and GP75-SS toggle latches

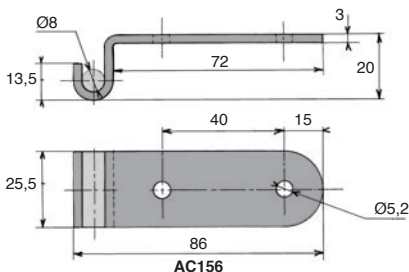

### DISCOUNTS


Qty	1+	51+	101+	250+	400+
Disc.	List	-10%	-15%	-20%	On request

Part N°	Material	Suitable for latch	Weight (g)	Stock*	Price each 1 to 49
<b>Right angled</b>					
AC156-ZB	Steel	GE32-ZB	59	-	0,88 €
AC156-SS	Stainless steel	GE32-SS	59	✓	4,04 €
<b>Flat</b>					
AC157-ZB	Steel	GE32-ZB	59	✓	0,88 €
AC157-SS	Stainless steel	GE32-SS	59	-	4,04 €

All dimensions in mm

**0 825 88 6000**  
Service 0,15 € / min  
+ prix appel

## Our other products

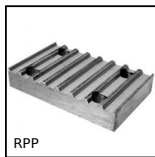

RPP

Connecting plate for RPP type timing belts, RRP5



BABV

Ball lock pins lockable, Stainless steel



MDB\_MTB

Moulded plastic bevel gear (nylon), 2:1



ETQ

Magnetic label holder for aluminium profile, Label holder



CHM110

Worm and wheel gear reducer, up to 980 Nm



HFL

One way needle bearing, Needle bearing



DBL821

Idler for slat top chain, Range 821



 
V3RA\_PTR

3-spoked handwheel with foldable handle, Polyamide



PRF\_ER

Joining bar for aluminium profile, Joint bar



G0

Steel spur gear, Steel 20NCD2



MHXred

Reducing sleeve male/female, Hexagonal - steel



NSU

Universal 90° support clamp, Universal 90° support clamp

## Complementary products



GE32

Sprung toggle latch with connecting link, Standard



AC156-157

Strike for toggle latch, 25.5mm