
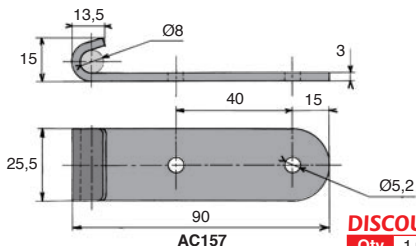


- Closed by latching
- Materials:
White zinc plated steel
18/8 stainless steel, natural finish

Accessories

- GP75-ZB and GP75-SS toggle latches

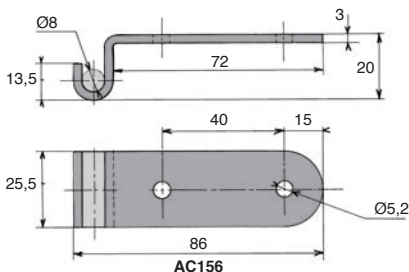

DISCOUNTS


Qty	1+	51+	101+	250+	400+
Disc.	List	-10%	-15%	-20%	On request

Part N°	Material	Suitable for latch	Weight (g)	Stock*	Price each 1 to 49
Right angled					
AC156-ZB	Steel	GE32-ZB	59	-	0,88 €
AC156-SS	Stainless steel	GE32-SS	59	✓	4,04 €
Flat					
AC157-ZB	Steel	GE32-ZB	59	✓	0,88 €
AC157-SS	Stainless steel	GE32-SS	59	-	4,04 €

All dimensions in mm

0 825 88 6000
Service 0,15 € / min
+ prix appel

 Our other products



MO

Wheel, Machined plastic (delrin)



BH02

Flange with bearing, Bearing secured with circlips



PLM-SC

Magnetic stud, With threaded hole



GA

Gas spring, Steel



 
VPRA_M

Hand wheel, Thermosetting plastic - galvanised steel hub



PTR

Idler chain sprocket, For standard applications



RPPM

RPP type belt by the metre, RPP8 Steel cored polyurethane



AT5P_AT10P

Connecting plate, AT10



DKN

Bellows coupling Gerwah®, from 0.4 to 10Nm



AXTR

Tensioner pulley, Shaft



DOMI80

DOMILINE - Adjustment slide, Slide DOMILINE 80



RFK28C

Hypoid gearbox - Stainless steel, up to 130 Nm

Complementary products



GE32

Sprung toggle latch with connecting link, Standard



AC156-157

Catch plate for toggle latch, 25.5mm