
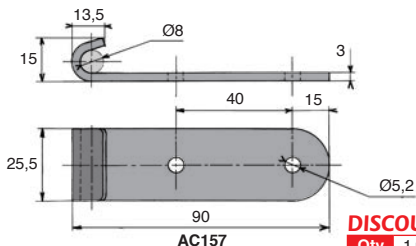


- Closed by latching
- Materials:
White zinc plated steel
18/8 stainless steel, natural finish

Accessories

- GP75-ZB and GP75-SS toggle latches

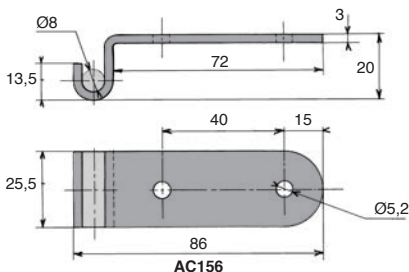

DISCOUNTS

Qty	1+	51+	101+	250+	400+
Disc.	List	-10%	-15%	-20%	On request

Part N°	Material	Suitable for latch	Weight (g)	Stock*	Price each 1 to 49
Right angled					
AC156-ZB	Steel	GE32-ZB	59	-	0,88 €
AC156-SS	Stainless steel	GE32-SS	59	✓	4,04 €
Flat					
AC157-ZB	Steel	GE32-ZB	59	✓	0,88 €
AC157-SS	Stainless steel	GE32-SS	59	-	4,04 €

All dimensions in mm

0 825 88 6000
Service 0,15 € / min
+ prix appel

Our other products



TCC_SS

Stainless steel rigging screw (hook/hook),
Stainless steel



G1

Steel spur gear, Steel
20NCD2



PTA150

Articulated levelling
foot, pressed base
Ø150, Ø 150



PLA

Flat magnet, Flat
magnet with thread



BPPL

Mini plain bearing ball
transfer unit, For
countersinking



PRF_JL6

Lip seal for panel,
Door seal - Ø 6mm



TRM

Spur round rack, Steel
- module 1-6



ECF

Well nut, Elastomer



PRF_CLIP_22

Cable clip for
aluminium profile, For



CLR

Straight clevis,
Straight clevis for use



G0

Steel spur gear, Steel
20NCD2



G-ECO

Eco range Spur gear,
Steel C45

Complementary products



GE32

Sprung toggle latch
with connecting link,
Standard



AC156-157

Strike for toggle latch,
25.5mm



AC156-157

Strike for toggle latch,
25.5mm