

- Suitable for transmitting high torque values

- Materials:

Steel C40/XC42



- Extruded product

Accessories

- Splined bush: cylindrical or flanged

Options

- Alternative lengths up to 3000mm

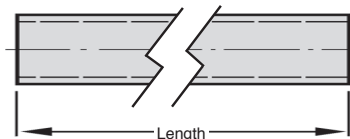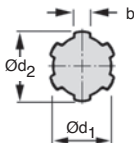


DISCOUNTS and AVAILABLE LENGTHS

| Qty | 1+ | 10+ | 20+ | 30+ | 40+ |
|-------|---------|------|---------|------|------------|
| disc | List | -15% | -20% | -30% | On request |
| L. | 1000 mm | | 2000 mm | | 3000 mm |
| Price | Uni. | | x 2,23 | | x 3,35 |

| Part number | Number of splines | Ød ₁ | Ød ₂ | b | Standard length (mm) | Weight (kg) | Stock* | Price each 1 to 9 |
|--------------|-------------------|----------------------------------------|----------------------------------------|-----------------------------------------|----------------------|-------------|--------|-------------------|
| ACA6-14-1000 | 6 | 11 ^{+0,08} / _{-0,08} | 14 ^{-0,07} / _{-0,2} | 3,0 ^{+0,08} / _{-0,08} | 1000 | 0,949 | ✓ | 28,84 € |
| ACA6-16-1000 | 6 | 13 ^{+0,08} / _{-0,08} | 16 ^{-0,07} / _{-0,2} | 3,5 ^{+0,08} / _{-0,08} | 1000 | 1,287 | ✓ | 27,62 € |
| ACA6-20-1000 | 6 | 16 ^{+0,08} / _{-0,08} | 20 ^{-0,07} / _{-0,25} | 4,0 ^{+0,08} / _{-0,08} | 1000 | 1,911 | ✓ | 37,05 € |
| ACA6-22-1000 | 6 | 18 ^{+0,08} / _{-0,08} | 22 ⁺⁰ / _{-0,10} | 5,0 ^{+0,08} / _{-0,08} | 1000 | 2,453 | ✓ | 41,99 € |
| ACA6-25-1000 | 6 | 21 ^{+0,08} / _{-0,08} | 25 ^{-0,07} / _{-0,27} | 5,0 ^{+0,08} / _{-0,08} | 1000 | 3,139 | ✓ | 48,01 € |
| ACA6-28-1000 | 6 | 23 ^{+0,08} / _{-0,08} | 28 ^{-0,07} / _{-0,25} | 6,0 ^{+0,08} / _{-0,08} | 1000 | 3,964 | ✓ | 64,54 € |
| ACA6-32-1000 | 6 | 26 ^{+0,08} / _{-0,08} | 32 ^{-0,07} / _{-0,27} | 6,0 ^{+0,08} / _{-0,08} | 1000 | 5,008 | ✓ | 79,05 € |
| ACA6-34-1000 | 6 | 28 ^{+0,08} / _{-0,08} | 34 ^{-0,07} / _{-0,27} | 7,0 ^{+0,08} / _{-0,08} | 1000 | 5,816 | ✓ | 93,28 € |
| ACA8-38-1000 | 8 | 32 ^{+0,08} / _{-0,08} | 38 ^{-0,07} / _{-0,27} | 6,0 ^{+0,08} / _{-0,08} | 1000 | 7,433 | ✓ | 115,68 € |
| ACA8-42-1000 | 8 | 36 ^{+0,08} / _{-0,08} | 42 ^{-0,07} / _{-0,27} | 7,0 ^{+0,08} / _{-0,08} | 1000 | 9,302 | ✓ | 150,14 € |
| ACA8-48-1000 | 8 | 42 ^{+0,08} / _{-0,08} | 48 ^{-0,07} / _{-0,27} | 8,0 ^{+0,08} / _{-0,08} | 1000 | 12,371 | ✓ | 190,46 € |
| ACA8-54-1000 | 8 | 46 ^{+0,08} / _{-0,08} | 54 ^{-0,07} / _{-0,27} | 9,0 ^{+0,08} / _{-0,08} | 1000 | 15,300 | ✓ | 277,15 € |

*Depending on availability - Dimensions in mm

Our other products

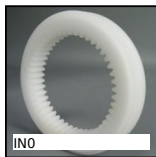

INO
Internal gear,
Machined plastic
(delrin)



PPD
Indexing plunger for
sheets, For sheet
metal



PAMF80EB
Articulated foot with
sheet metal base
Ø80, Articulated foot



HG5-ECO
Eco range Spur gear,
Steel C45



IBjss
Ball and socket joint,
Stainless steel




YG3
HEAVY DUTY spur
gear, Steel 35NCD6



BLHT40
Right angled gearbox,
from 4 to 10.30 Nm



 G0
Steel spur gear, Steel
20NCD2



CHB
Worm and wheel gear
reducer, up to 22 Nm



GP75
Spring loaded toggle
latch, Standard
(GP75)



BPHRF
Ball transfer unit
housed spring loaded,
High



ACL
Joints for aluminium
profile, Variable angle
hinge

Complementary products



BCA
Steel splined collar,
Steel



ACAss
Stainless steel splined
shaft, Stainless steel