

Stainless steel 304 splined shaft

ACAss

Parallel-faced

- Suitable for transmitting high torque values

- Material:



Stainless steel 304 (1.4301)

Accessoires

- Stainless steel splined bush BCAss

Option

- Alternative lengths up to 3000mm

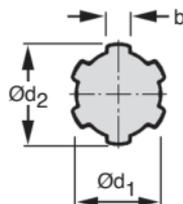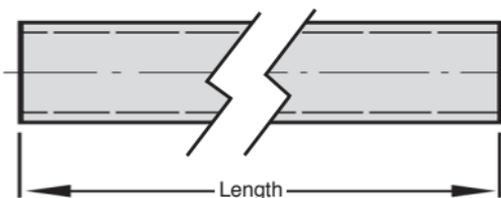

For hostile environments

NEW!
Replace the part
number BUC30

DISCOUNTS

Qty	1+	2+	20+
Disc.	List	-10%	On request

Part number	Number of splines	$\varnothing d_1^{+0/-0,08}$	$\varnothing d_2^{-0,07/-0,27}$	$b^{+0/-0,08}$	Standard length (mm)	Weight (kg/m)	Price each for 1000mm
ACA6-14-1000/SS	6	11,00	14,00	3,00	1000	0,949	57,56 €
ACA6-16-1000/SS	6	13,00	16,00	3,50	1000	1,287	67,43 €
ACA6-20-1000/SS	6	16,00	20,00	4,00	1000	1,911	119,37 €
ACA6-25-1000/SS	6	21,00	25,00	5,00	1000	3,139	195,47 €
ACA6-32-1000/SS	6	26,00	32,00	6,00	1000	5,008	299,45 €
ACA8-38-1000/SS	8	32,00	38,00	6,00	1000	7,433	429,45 €

Dimensions in mm

Our other products



RJA10_03

Sealing strip, Clipping



SDCss

Positioning sleeve for indexing pin, For pin Ø4 to Ø12



SLB

Indexing plunger, steel class 5.8



BIMSS

Indexing plunger mini, miniature - Stainless steel



BPH

Ball transfer unit plain fit, High



SERB

Universal latch key, Universal latch key



FF40

Offset spur gear reducer, from 59 to 210 Nm



EKONSL

Silicone conical elasto buffer, Female mounting



CLG2

Moulded plastic spur gear, Moulded plastic



BLHM20

Right angled gearbox, double output shafts,



PSG35

Spur gear - precision range, Stainless steel



BL8

Right angled gearbox, from 0.20 to 2 Nm

Complementary products



BCAss

Stainless steel splined bush, Inox



ACA

Steel splined shaft, Steel