

# Stainless steel 304 splined shaft

## ACAss

## Parallel-faced

- Suitable for transmitting high torque values

- Material:



Stainless steel 304 (1.4301)

### Accessoires

- Stainless steel splined bush BCAss

### Option

- Alternative lengths up to 3000mm

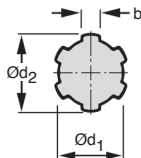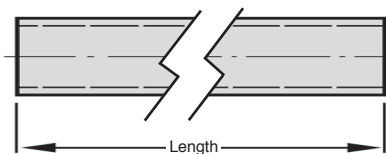

For hostile environments

**NEW!**  
Replace the part  
number BUC30

### DISCOUNTS

Qty	1+	2+	20+
Disc.	List	-10%	On request

Part number	Number of splines	$\overset{+0}{\underset{-0,08}{\text{Ød1}}}$	$\overset{-0,07}{\underset{-0,27}{\text{Ød2}}}$	$\overset{+0}{\underset{-0,08}{\text{b}}}$	Standard length (mm)	Weight (kg/m)	Price each for 1000mm
ACA6-14-1000/SS	6	11,00	14,00	3,00	1000	0,949	57,56 €
ACA6-16-1000/SS	6	13,00	16,00	3,50	1000	1,287	67,43 €
ACA6-20-1000/SS	6	16,00	20,00	4,00	1000	1,911	119,37 €
ACA6-25-1000/SS	6	21,00	25,00	5,00	1000	3,139	195,47 €
ACA6-32-1000/SS	6	26,00	32,00	6,00	1000	5,008	299,45 €
ACA8-38-1000/SS	8	32,00	38,00	6,00	1000	7,433	429,45 €

Dimensions in mm

## Our other products



PFM

Fixed levelling foot,  
Flanged plate



PRF\_JL4

Lip seal for panel,  
Door seal - Ø 4mm



 
SA\_SAKH

Housing for linear  
bearing, Closed - light  
load



SEH

Horizontal stirrup  
toggle clamp,  
Horizontal Latch  
clamp - stainless ...



QNUP

Single row cylindrical  
roller bearing, 1 fixed  
inner flange and 1 fr...



PO

Pull handle - Multi-  
sector, Smooth hole



RJUM01

Closed polymer  
Drylin® R bearing,  
Drylin® R



PR40

Articulated foot Ø40,  
Ø 40



T2

T type timing belt,  
T2.5 Steel cored



HTD5M-BAR

HTD type tooth bar  
stock, HTD5



CHB

Feet, For CHB gearbox



DKONSL

Silicone conical elasto  
buffer, Male mounting

## Complementary products



BCAss

Stainless steel splined  
bush, Inox



ACA

Steel splined shaft,  
Steel