

Stainless steel 304 splined shaft

ACAss

Parallel-faced

- Suitable for transmitting high torque values

- Material:



Stainless steel 304 (1.4301)

Accessoires

- Stainless steel splined bush BCAss

Option

- Alternative lengths up to 3000mm

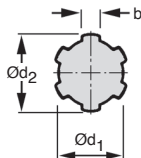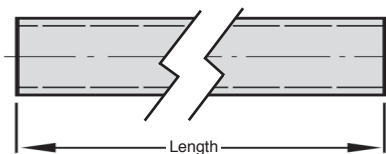

For hostile environments

NEW!
Replace the part
number BUC30

DISCOUNTS

Qty	1+	2+	20+
Disc.	List	-10%	On request

Part number	Number of splines	$\varnothing d_1^{+0/-0,08}$	$\varnothing d_2^{-0,07/-0,27}$	$b^{+0/-0,08}$	Standard length (mm)	Weight (kg/m)	Price each for 1000mm
ACA6-14-1000/SS	6	11,00	14,00	3,00	1000	0,949	57,56 €
ACA6-16-1000/SS	6	13,00	16,00	3,50	1000	1,287	67,43 €
ACA6-20-1000/SS	6	16,00	20,00	4,00	1000	1,911	119,37 €
ACA6-25-1000/SS	6	21,00	25,00	5,00	1000	3,139	195,47 €
ACA6-32-1000/SS	6	26,00	32,00	6,00	1000	5,008	299,45 €
ACA8-38-1000/SS	8	32,00	38,00	6,00	1000	7,433	429,45 €

Dimensions in mm

Our other products



DCG

Suction cup, 2.5 bellows, silicon



SCA

Flat cable clamp, Steel



EMAS

Antistatic knurled nut, Antistatic



ES

Simple support base (bipod), Plastic



CHM50

Worm and wheel gear reducer, up to 107 Nm



TIF

Threaded rod - DIN975, Stainless steel A2



BLH70

Right angled gearbox, from 26 to 128 Nm



 
RPP

Connecting plate for RPP type timing belts, RRP5



CFS

Miniature cam follower, Miniature



RPP5

RPP heavy duty timing belt, RPP5



T5M T10M

T type timing belt per metre, T10 Steel cored polyurethane



LPCM

Lever with cylindrical handle, Black Duroplast, steel lever

Complementary products



BCAss

Stainless steel splined bush, Inox



ACA

Steel splined shaft, Steel