

Stainless steel 304 splined shaft

ACAss

Parallel-faced

- Suitable for transmitting high torque values

- Material:



Stainless steel 304 (1.4301)

Accessoires

- Stainless steel splined bush BCAss

Option

- Alternative lengths up to 3000mm

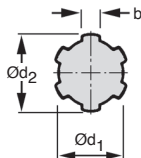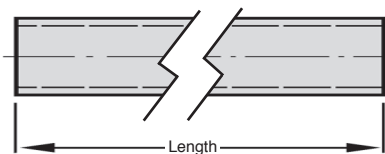

For hostile environments

NEW!
Replace the part
number BUC30

DISCOUNTS

Qty	1+	2+	20+
Disc.	List	-10%	On request

Part number	Number of splines	$\overset{+0}{\underset{-0,08}{\text{Ød1}}}$	$\overset{-0,07}{\underset{-0,27}{\text{Ød2}}}$	$\overset{+0}{\underset{-0,08}{\text{b}}}$	Standard length (mm)	Weight (kg/m)	Price each for 1000mm
ACA6-14-1000/SS	6	11,00	14,00	3,00	1000	0,949	57,56 €
ACA6-16-1000/SS	6	13,00	16,00	3,50	1000	1,287	67,43 €
ACA6-20-1000/SS	6	16,00	20,00	4,00	1000	1,911	119,37 €
ACA6-25-1000/SS	6	21,00	25,00	5,00	1000	3,139	195,47 €
ACA6-32-1000/SS	6	26,00	32,00	6,00	1000	5,008	299,45 €
ACA8-38-1000/SS	8	32,00	38,00	6,00	1000	7,433	429,45 €

Dimensions in mm

Our other products



CM

Tools Hygienic Usit® and Hygienic Design®, Combination spanner



CHAL3

Piano hinge, Aluminium



J51

Spur gear coaxial gearbox, from 0.13 to 0.49 Nm - Inline



UCP

Cast iron pillow block bearing, Cast iron



CDPC

Flanged drill bushing, Steel



GCT

Pipe linch pin, Tube linch pin



ZG2

Plastic spur gear, Machined plastic (delrin)



HW_HT

Half-rail guide, Rail



CLG1

Moulded plastic spur gear, Moulded plastic (nylon)



DHX

Dowel pin internal thread, Extractable DIN 7979D



CHM90

Worm and wheel gear reducer, up to 540 Nm



DOG319

Motor-gearbox 12V and 24V DC, from 4 to 9 Nm

Complementary products



BCAss

Stainless steel splined bush, Inox



ACA

Steel splined shaft, Steel