

# Stainless steel 304 splined shaft

## ACAss

## Parallel-faced

- Suitable for transmitting high torque values

- Material:



Stainless steel 304 (1.4301)

### Accessoires

- Stainless steel splined bush BCAss

### Option

- Alternative lengths up to 3000mm

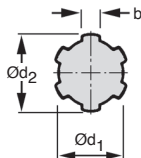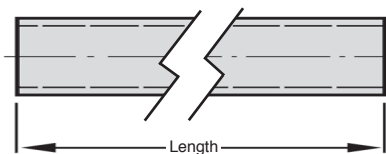

For hostile environments

**NEW!**  
Replace the part  
number BUC30

### DISCOUNTS

Qty	1+	2+	20+
Disc.	List	-10%	On request

Part number	Number of splines	$\varnothing d_1^{+0/-0,08}$	$\varnothing d_2^{-0,07/-0,27}$	$b^{+0/-0,08}$	Standard length (mm)	Weight (kg/m)	Price each for 1000mm
ACA6-14-1000/SS	6	11,00	14,00	3,00	1000	0,949	57,56 €
ACA6-16-1000/SS	6	13,00	16,00	3,50	1000	1,287	67,43 €
ACA6-20-1000/SS	6	16,00	20,00	4,00	1000	1,911	119,37 €
ACA6-25-1000/SS	6	21,00	25,00	5,00	1000	3,139	195,47 €
ACA6-32-1000/SS	6	26,00	32,00	6,00	1000	5,008	299,45 €
ACA8-38-1000/SS	8	32,00	38,00	6,00	1000	7,433	429,45 €

Dimensions in mm

## Our other products



**EKONSL**  
Silicone conical elasto  
buffer, Female  
mounting




**DBL820**  
Idler for slat top  
chain, Ranges 820  
and 815



**CHINV**  
Invisible hinge,  
Invisible - 90° opening



 **M0**  
Worm and wheel set,  
Non hardened steel



**NANO**  
Speed controller 3A, 3  
A




**BLHM20**  
Right angled gearbox,  
double output shafts,  
up to 1.77 Nm



**H2**  
Crossed helical gear  
crossed axis at 90°,  
Steel 20NCD2



 **RAS**  
90°ball and socket  
joints DIN71802,  
Stainless steel



**PM2**  
Worm , Machined  
plastic (delrin)



**BDPR**  
Holding arm, Rigid



**GCL**  
Linear ball slide -  
Stainless steel balls,



**SBS\_L**  
Chain link, Stainless  
steel

## Complementary products



**BCAss**  
Stainless steel splined  
bush, Inco



**ACA**  
Steel splined shaft,  
Steel