

# Door stop for aluminium profile




## Magnetic closing

## ACLAPB

- **Quick door closing system**
- **Materials:**
  - Glass fibre reinforced PA plastic
  - Neodymium magnet
  - Steel counter plate and screws

### Advantages

- Discrete stop
- Small size, takes up little space inside the machine

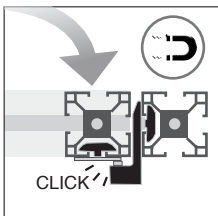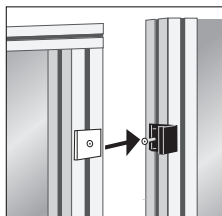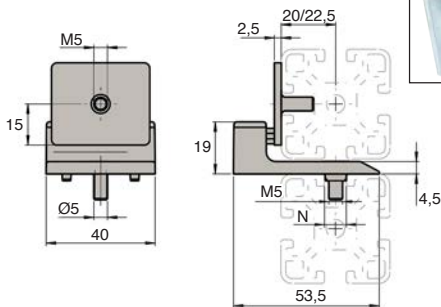

Typical application

### DISCOUNTS

Qty	1+	50+	100+
Disc.	Net	-5%	On request

Part N°	N	Holding force (N)	Weight (g)	Price each 1 to 49
ACL-APB-53	8/10	30	53	12,30 €

All dimensions in mm

**0 825 88 6000**  
Service 0,15 € / min  
+ prix appel

Fax

cial2@hpceurope.com

**HPC**

SUPPLEMENT 2019

239

## Our other products



ZBconique

Machined plastic  
bevel gear , 1:1



PM3

Worm and wheel set,  
Non hardened steel



SKM

Hexagonal steel nut,  
Steel - 1 thread



PITA

Locking bolt, with T  
handle



BPM-Z

Plastic slotted spring  
plunger with ball tip,  
Plastic body +  
plastic...



WING

Manually tightened  
wing nut, Stainless  
steel DIN 314/315



RUR

Wheel, Polyurethane -  
Aluminium rim (Free  
running)



BOX-CS

Hose clamp, Box set  
of steel hose clamps



PSG05

Spur gear - precision  
range, Pre-hardened



TOC

Short swivel head,  
Short



GE1006

Elastic ringed latch,  
Hooks into a slot



SC2

2 part rigid shaft  
clamp, Clamping jaw

## Complementary products



ACLAPA

Magnetic stop for  
aluminium profile,  
Magnetic stop



ACLBDB

Closing mechanism  
for aluminium profile,  
Dual ball catch