

Door stop for aluminium profile

Magnetic closing

ACLAPB



- Quick door closing system

- Materials:

Glass fibre reinforced PA plastic
Neodymium magnet
Steel counter plate and screws

Advantages

- Discrete stop
- Small size, takes up little space inside the machine

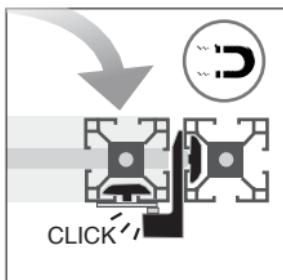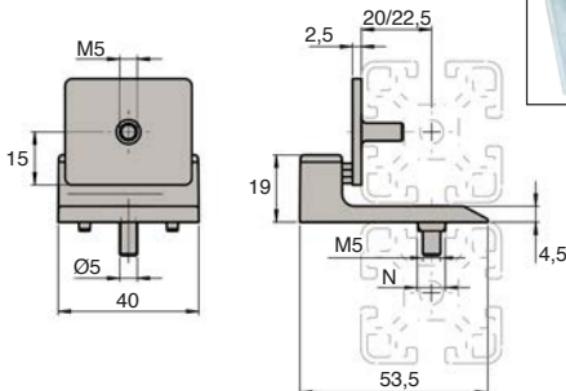

Typical application

DISCOUNTS

Qty	1+	50+	100+
Disc.	Net	-5%	On request

Part N°	N	Holding force (N)	Weight (g)	Price each
ACL-APB-53	8/10	30	53	12,30 €

All dimensions in mm

Fax

0 825 88 6000

Service 0,15 €/min
+ prix appel

cial2@hpceurope.com

HPC

SUPPLEMENT 2019

239

Our other products



AFSE
Locking pin with interlocking safety latch, with interlocking safety...



PRF-GPB
Guide for aluminium profile, Rail for 8mm wide slots



HTD14M_85
HTD Heavy duty timing pulley, HTD14 Cast



AT5-16ECO
AT type timing pulley, Economy range - AT5 aluminium



DOMI80
Accessories, Fixing kit



CHB
Worm and wheel gear reducer, up to 41 Nm



BLHB40
Right angled gearbox, bored shafts, up to 10.3 Nm



MET
Cylindrical sintered bronze bush, Self-lubricating sintered bronze



KS
Keysteel, Stainless steel - Keystock



SBF
Sealed flange bearing unit for Food Industry, cover



BLHM40
Right angled gearbox, double output shafts, up to 10.3 Nm



BPMc
Stainless steel slotted spring plunger with ceramic ball tip, 303 St...

Complementary products



ACLAPA
Magnetic stop for aluminium profile, Magnetic stop



ACLBDB
Closing mechanism for aluminium profile, Dual ball catch