

Door stop for aluminium profile




Magnetic closing

ACLAPB

- **Quick door closing system**
- **Materials:**
 - Glass fibre reinforced PA plastic
 - Neodymium magnet
 - Steel counter plate and screws

Advantages

- Discrete stop
- Small size, takes up little space inside the machine

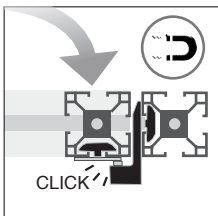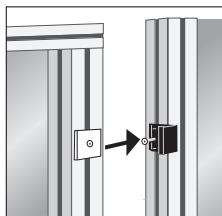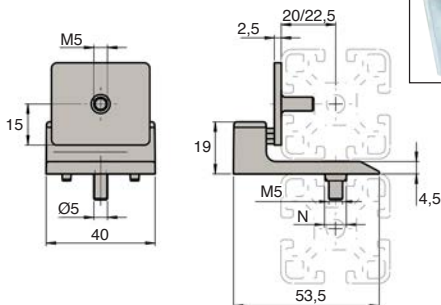

Typical application

DISCOUNTS

Qty	1+	50+	100+
Disc. Net		-5%	On request

Part N°	N	Holding force (N)	Weight (g)	Price each 1 to 49
ACL-APB-53	8/10	30	53	12,30 €

All dimensions in mm

0 825 88 6000
Service 0,15 € / min
+ prix appel

Fax

cial2@hpceurope.com

HPC

SUPPLEMENT 2019

239

Our other products



SVR15

Screwjack with travelling nut, with moving nut



SHN

Hexagonal nut DIN934, Steel (Class 6[8])



RFV50

Stainless steel worm and wheel gearbox, up to 80 Nm



DOMI50

Accessories, Fixing kit



SA_SAKH

Housing for linear bearing, Closed - light load



BABS

630 Stainless steel compact ball pin, Hardened stainless steel



G2

Steel spur gear, Steel 20NCD2



RPCpl

Fixed castor with plate, Steel - Polyamide



SCA_SS

Stainless steel flat cable clamp, Stainless



SVG

Adjustable latch clamp with strike



SVT15

Screwjack with travelling screw, with



PW_PWG25

Worm - precision range, Stainless steel

Complementary products



ACLAPA

Magnetic stop for aluminium profile, Magnetic stop



ACLBDB

Closing mechanism for aluminium profile, Dual ball catch