

Connection plate for aluminium profile

ACLPL For pre-assembled connection

- For connecting two structures together
- Connection of 2 aluminium profiles
- Corner reinforcement
- Material:
Anodised aluminium

Info.



- Supplied without fixing kit (see button head screw **BHC8-16/SS/B** or **BHC8-20/SS** and slot nut **PRF-ECL-M8/SS**)





Typical application

Anodised aluminium

Aluminium profile

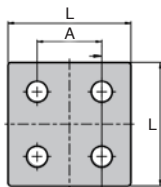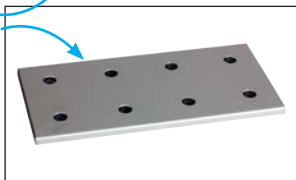

ACL-PL-9090

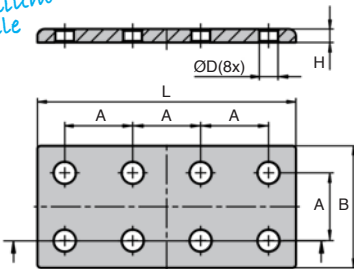 

ACL-PL-90180


DISCOUNTS

Qty	1+	50+	100+
Disc.	Net	-5%	On request

Part N°	L	B	H	A	ØD	Weight (g)	Price each 1 to 49
Square							
ACL-PL-9090	86	-	6	45	9	115	6,63 €
Rectangular							
ACL-PL-90180	176	86	6	45	9	240	11,30 €

All dimensions in mm

 Our other products



GPLny

Brush, nylon



RT25ss

Self-centering flanged locking assembly, Medium/high torque



GSI_A

Stainless steel adjustable gas spring, Stainless steel



KKB-AR

Linear bearing with inclined ball tracks, Standard loads / -20° +20...



SBF

Sealed flange bearing unit for Food Industry, cover



PW_PWG1

Wheel - precision range, Bronze



DIA

Ring operated locking bolt, with ring



BLH60

Right angled gearbox, from 19 to 70 Nm



HTD8M_30

HTD Heavy duty timing pulley, HTD8



J65

Spur gear coaxial gearbox, from 0.80 to



M1

Worm and wheel set, Machined plastic



GE_C

Spherical bushing, Hard chromium / PTFE

Complementary products



BHC

Socket head button screw, Stainless steel A2



 
PRF_ECL

Nut for aluminium profile, Stainless steel square nut with tab



ACL-PL

Joining plate for aluminium profile, Joint plate - 86x86 mm



ACL-PLAngle

Joining plate for aluminium profile, Angle connection