

Connection plate for aluminium profile

ACLPL For pre-assembled connection

- For connecting two structures together
- Connection of 2 aluminium profiles
- Corner reinforcement
- Material:
Anodised aluminium

Info.


 

- Supplied without fixing kit (see button head screw **BHC8-16/SS/B** or **BHC8-20/SS** and slot nut **PRF-ECL-M8/SS**)





Typical application

Anodised aluminium

Aluminium profile

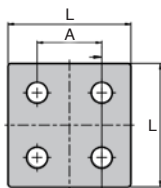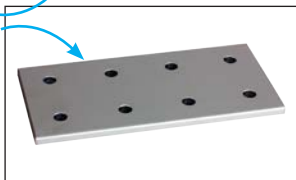

ACL-PL-9090

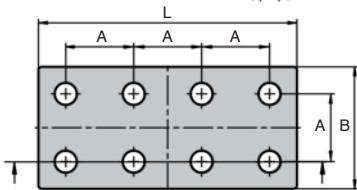 

ACL-PL-90180

DISCOUNTS

Qty	1+	50+	100+
Disc.	Net	-5%	On request

Part N°	L	B	H	A	ØD	Weight (g)	Price each 1 to 49
Square							
ACL-PL-9090	86	-	6	45	9	115	6,63 €
Rectangular							
ACL-PL-90180	176	86	6	45	9	240	11,30 €

All dimensions in mm

Our other products



PLC_PLT

Magnetic stud with threaded hole, With threaded hole



CHAFR-MINI

Miniature friction hinge, Friction



BPHRF

Ball transfer unit housed spring loaded, High



R205

Die spring ISO10243, Heavy



 
HK

Manual locking clamp, Manual locking clamp LRX



CHTRP

Single and dual output gearboxes, Up to 34,5 Nm



M1

Worm and wheel set, Bronze



PLM-C

Cylindrical holding magnets, Cylindrical holding magnet



RFK28C

Hypoid gearbox - Stainless steel, up to



PCS50

Chain sprocket - steel, 12.7mm (DIN08B-1)



RGS

Rotex® GS backlash free jaw coupling,



BAC110

Swivel storage bin, Adjustable support

Complementary products



BHC

Socket head button screw, Stainless steel A2



PRF_ECL

Nut for aluminium profile, Stainless steel square nut with tab



ACL-PL

Joining plate for aluminium profile, Joint plate - 86x86 mm



ACL-PLAngle

Joining plate for aluminium profile, Angle connection