

# Connection plate for aluminium profile

## ACLPL For pre-assembled connection

- For connecting two structures together
- Connection of 2 aluminium profiles
- Corner reinforcement
- Material:  
Anodised aluminium

### Info.



- Supplied without fixing kit (see button head screw **BHC8-16/SS/B** or **BHC8-20/SS** and slot nut **PRF-ECL-M8/SS**)





Typical application

Anodised aluminium

Aluminium profile

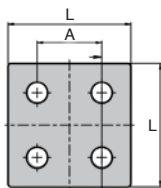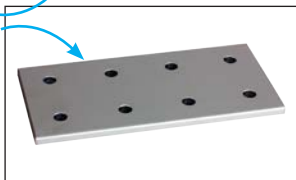

ACL-PL-9090

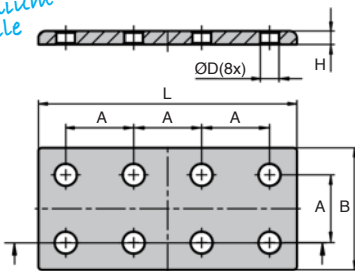 

ACL-PL-90180


### DISCOUNTS

 Qty	1+	50+	100+
Disc.	Net	-5%	On request

Part N°	L	B	H	A	ØD	Weight (g)	Price each 1 to 49
<b>Square</b>							
ACL-PL-9090	86	-	6	45	9	115	6,63 €
<b>Rectangular</b>							
ACL-PL-90180	176	86	6	45	9	240	11,30 €

All dimensions in mm

## Our other products



M1

Worm and wheel set,  
Bronze



PRF4590

Standard aluminium  
profile, 45 x 90 mm



PRF JL5

Lip seal for panel,  
Door seal - Ø 5mm



HTD14M\_85

HTD Heavy duty  
timing pulley, HTD14  
Steel



EIM

Stainless steel U bolt,  
Stainless steel



BPTR\_M

End cap with threaded  
insert for round tube,  
With threaded insert



PCS37

Chain sprocket - steel,  
9.525mm (DIN06B-1)



RVM25

Manually operated  
gearbox, Bevel



PITA

Locking bolt, with T  
handle



RAS

90° ball and socket  
joints DIN71802, Steel



SLV

Vertical toggle clamp,  
Vertical Lever Clamp -  
steel



MACss

Stainless steel  
carabiner, Stainless  
steel

## Complementary products



BHC

Socket head button  
screw, Stainless steel  
A2



PRF\_ECL

Nut for aluminium  
profile, Stainless steel  
square nut with tab



ACL-PL

Joining plate for  
aluminium profile,  
Joint plate - 176x86  
mm



ACL-PLAngle

Joining plate for  
aluminium profile,  
Angle connection