

Connection plate for aluminium profile

ACLPL For pre-assembled connection

- For connecting two structures together
- Connection of 2 aluminium profiles
- Corner reinforcement
- Material:
Anodised aluminium

Info.



- Supplied without fixing kit (see button head screw **BHC8-16/SS/B** or **BHC8-20/SS** and slot nut **PRF-ECL-M8/SS**)





Typical application

Anodised aluminium

Aluminium profile

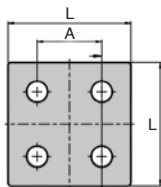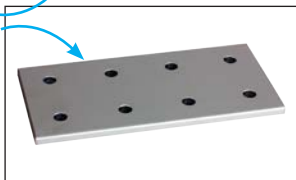

ACL-PL-9090

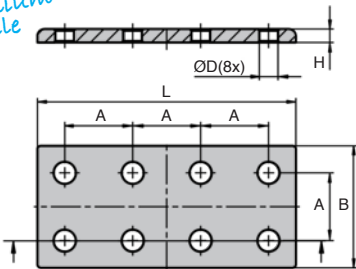 

ACL-PL-90180

DISCOUNTS

Qty	1+	50+	100+
Disc.	Net	-5%	On request

Part N°	L	B	H	A	ØD	Weight (g)	Price each 1 to 49
Square							
ACL-PL-9090	86	-	6	45	9	115	6,63 €
Rectangular							
ACL-PL-90180	176	86	6	45	9	240	11,30 €

All dimensions in mm

Our other products



LF
Precision locknut,
Precision locknut



RFV40
Stainless steel worm
and wheel gearbox,
up to 47 Nm



SFE
Female rod ends,
Stainless steel / PTFE



AT5P_AT10P
Connecting plate for
AT type timing belts,
AT10



VDSQ
Sliding lock
adjustment system,
Sliding lock for square
profile



CLASS
Stainless steel
indexing handle -
female, Stainless steel



PR125
Articulated foot Ø123,
Ø 123



PRF_CLIP_22
Cable clip for
aluminium profile, For
electric and
pneumatic cables



HK
Manual locking clamp,
Manual locking clamp
LRX



BAC105
Storage bin, 8mm



PRF_GAL
Roller for aluminium
profile, Flat roller



BH01
Single housed
bearing, Bearing fitted
with adhesive

Complementary products



BHC
Socket head button
screw, Stainless steel
A2



PRF_ECL
Nut for aluminium
profile, Stainless steel
square nut with tab



ACL-PL
Joining plate for
aluminium profile,
Joint plate - 86x86
mm



ACL-PLAngle
Joining plate for
aluminium profile,
Angle connection