

Connection plate for aluminium profile


Angle connection

ACLPL

- Connection of 2 aluminium profiles
- Corner reinforcement
- Material:
Anodised aluminium

Info.


- Supplied without fixing kit (see button head screw BHC8-16/SS/B or BHC8-20/SS and slot nut PRF-ECL-M8/SS)

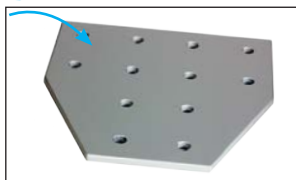


Anodised aluminium



Typical application

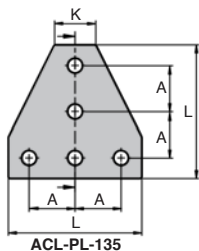

ACL-PL-135

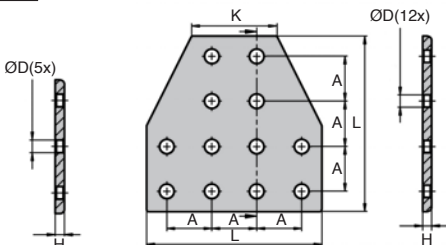

ACL-PL-180

DISCOUNTS

Qty	1+	50+	100+
Disc. Net	-5%	On request	

Part N°	L	H	A	K	ØD	Weight (g)	Price each
ACL-PL-135	131	6	45	41	9	210	14,57 €
ACL-PL-180	176	6	45	86	9	425	23,94 €

All dimensions in mm

0 825 88 6000
Service 0,15 € / min
+ prix appel

Fax

cial2@hpceurope.com

HPC

SUPPLEMENT 2019

243

Our other products



PRF_PGN

Door handle for aluminium profile, Handle with lock suitable



PR125rehausse

Extension for articulated foot Ø123, articulated foot PR125



ZBconique

Machined plastic bevel gear, 1:1



BDPR

Holding arm, Rigid



PDM_PDV

Detectable plastic palm grip, blue thermoplastic



PRF_ROUL

Castor for aluminium profile, No brake



UFX

Uneflex® elastic coupling, range



PCS_PA6

Plastic sprocket, 12.7mm (DIN 08B-1)



SLB

Indexing plunger, stainless steel



AT5courroie

AT type timing belt, AT5 Steel cored



PRF_CH

Cable-carrier chain for aluminium profile,



FGWA

End support, With base

Complementary products



BHC

Socket head button screw, Stainless steel A2



PRF_ECL

Nut for aluminium profile, Stainless steel square nut with tab