

Connection plate for aluminium profile


Angle connection

ACLPL

- Connection of 2 aluminium profiles
- Corner reinforcement
- Material:
Anodised aluminium

Info.




- Supplied without fixing kit (see button head screw BHC8-16/SS/B or BHC8-20/SS and slot nut PRF-ECL-M8/SS)

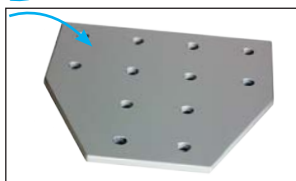

Anodised aluminium



 Typical application

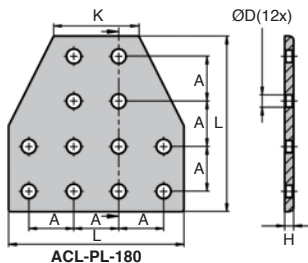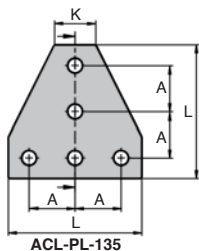

DISCOUNTS

Qty	1+	50+	100+
Disc. Net		-5%	On request

Part N°	L	H	A	K	ØD	Weight (g)	Price each
ACL-PL-135	131	6	45	41	9	210	14,57 €
ACL-PL-180	176	6	45	86	9	425	23,94 €

All dimensions in mm

0 825 88 6000
Service 0,15 € / min
+ prix appel

Fax

cial2@hpceurope.com

HPC

SUPPLEMENT 2019

243

Our other products



ZBconique

Machined plastic
bevel gear , 1:1



TCL-ECL

Adjusting nut, Fine
thread



FBL6000_K13

Brush strip per meter
PP fibres Ø0.2, Black
striated polypropylene



PRF_BM

Base support plate for
aluminium profile,
Central base fixation



BLHB50

Right angled gearbox,
bored shafts, up to 30
Nm



PPS

Lifting ring, Universal
threaded



GEC

Rubber latch clamp
with strike plate,
Lockable



CHAR16046

Spring hinge, screwed



LWL

Linear ball slide -
Stainless steel balls,



UTKpocr

Utilittrak® 3 wheels
carriage, Polymer



PAP

Handle for aluminium
profile, Ergonomic



HS

Hexagonal spacer,
Stainless steel 303

Complementary products



BHC

Socket head button
screw, Stainless steel
A2



PRF_ECL

Nut for aluminium
profile, Stainless steel
square nut with tab