

Connection plate for aluminium profile

ACLPR

Right angled connection

- **Corner reinforcement**
- Connection of 2 aluminium profiles at a right angle
- Material:
Anodised aluminium



Info.

- Supplied without fixing kit (see button head screw **BHC8-16/SS/B** or **BHC8-20/SS** and slot nut **PRF-ECL-M8/SS**)

Anodised aluminium



Typical application

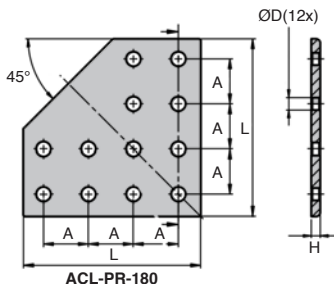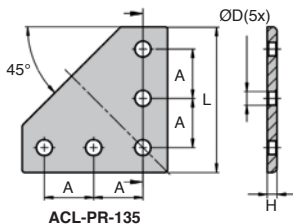

DISCOUNTS

Qty	1+	50+	100+
Disc. Net	-5%	On request	

Part N°	L	H	A	ØD	Weight (g)	Price each 1 to 49
ACL-PR-135	133	6	45	9	215	13,63 €
ACL-PR-180	178	6	45	9	435	22,16 €

All dimensions in mm

Our other products



SCH
Horizontal hook
toggle clamp,
Horizontal Hook
clamp - steel



LVT
Miniature motorised
actuator 1A, 1 amper



NK40
Drylin®N miniature
guiding system, Withd
40 mm



WFRM
Flanged polymer nut,
Polymer (Iglidur®) - 1
thread



PRF_CH
Cable-carrier chain for
aluminium profile,
Supplied in metre
lengths



DILC
Indexing plunger with
cam, with cam



VELM4
Screw-on base for
hook-and-loop strip,
Polyamide



HTD5M_25
HTD Heavy duty
timing pulley, HTD5
Aluminium



PTRSS
Idler chain sprocket,
For hostile
environments



CM
Tools Hygienic Usit®
and Hygienic
Design®,



WSSss
Symmetrical S shaped
hook stainless steel,
Stainless steel



PCLA_T
Technopolymer
clamping lever - male,
Plastic

Complementary products



BHC
Socket head button
screw, Stainless steel
A2



PRF_ECL
Nut for aluminium
profile, Stainless steel
square nut with tab



ACL-PL
Joining plate for
aluminium profile,
Joint plate - 176x86
mm



ACL-PR
Joining plate for
aluminium profile,
Right angled
connection