

Connection plate for aluminium profile

ACLPR

Right angled connection

- **Corner reinforcement**
- Connection of 2 aluminium profiles at a right angle
- Material:
Anodised aluminium



Info.

- Supplied without fixing kit (see button head screw **BHC8-16/SS/B** or **BHC8-20/SS** and slot nut **PRF-ECL-M8/SS**)

Anodised aluminium



Typical application

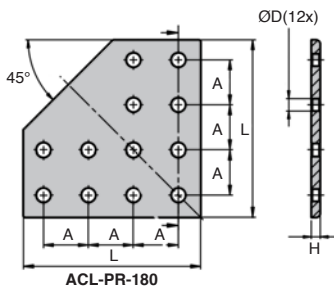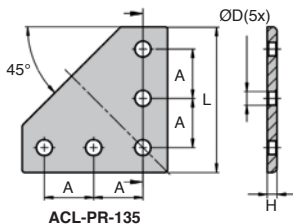

DISCOUNTS

Qty	1+	50+	100+
Disc. Net	-5%	On request	

Part N°	L	H	A	ØD	Weight (g)	Price each 1 to 49
ACL-PR-135	133	6	45	9	215	13,63 €
ACL-PR-180	178	6	45	9	435	22,16 €

All dimensions in mm

Our other products



CHAL3

Piano hinge,
Aluminium



DCG

Suction cup, 2.5
bellows, nitrile



S_2R5

Deep groove ball
bearing, Stainless
steel



LVT

Miniature motorised
actuator 2A, 2 amperes



GPLso

Brush, silk



E60B

Right angle helical
reducers, from 4.50 to
24 Nm



MBEX

Hexagonal ended
handle, Hexagonal
ended handle



VRM

Female swivelling
lifting rings, Female
swivelling



DCA

Suction cup, 1.5
bellows, silicon



SUA4

Single chain supplied
by the metre, Steel



SH0

Parallel axis helical
gear, Machined plastic



RTTss

Locking assembly,
Medium/high torque

Complementary products



BHC

Socket head button
screw, Stainless steel
A2



PRF_ECL

Nut for aluminium
profile, Stainless steel
square nut with tab



ACL-PL

Joining plate for
aluminium profile,
Joint plate - 176x86
mm



ACL-PR

Joining plate for
aluminium profile,
Right angled
connection