

Connection plate for aluminium profile

ACLPR

Right angled connection

- **Corner reinforcement**
- Connection of 2 aluminium profiles at a right angle
- Material:
Anodised aluminium



Info.

- Supplied without fixing kit (see button head screw **BHC8-16/SS/B** or **BHC8-20/SS** and slot nut **PRF-ECL-M8/SS**)

Anodised aluminium



Typical application

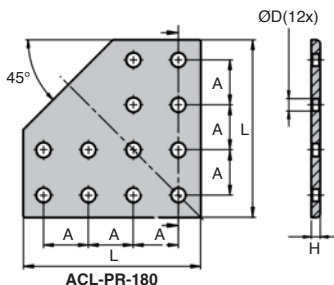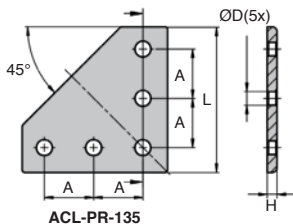

DISCOUNTS

Qty	1+	50+	100+
Disc. Net	-5%	On request	

Part N°	L	H	A	ØD	Weight (g)	Price each 1 to 49
ACL-PR-135	133	6	45	9	215	13,63 €
ACL-PR-180	178	6	45	9	435	22,16 €

All dimensions in mm

Our other products



ACLERP

Roller block for aluminium profile, With guide rail



CHAR7520

Spring hinge, screwed



PSG05

Spur gear - precision range, Pre-hardened Steel 35NCD6



BEF

Bearing housing for miniature ballscrew, Bearing housing



PGM52-M4

Pull handle, Aluminium



 
ACL-APB

Closing system for aluminium profile, Magnetic door stop



BUT

Panel stop, Panel stop



PO

Pull handle - Multi-sector, Smooth hole



PRF-GUM

Aluminium profile anodising polisher, Polishing block



CHA1056_U4

Screw-in hinge, Section 40X40



PPG

Indexing plunger with flange, With horizontal mounting



GP

Spring loaded toggle latch, With padlock-holder

Complementary products



BHC

Socket head button screw, Stainless steel A2



PRF_ECL

Nut for aluminium profile, Stainless steel square nut with tab



ACL-PL

Joining plate for aluminium profile, Joint plate - 176x86 mm



ACL-PL

Joining plate for aluminium profile, Joint plate - 86x86 mm