

# Connection plate for aluminium profile

## ACLPR



## Right angled connection

- **Corner reinforcement**
- Connection of 2 aluminium profiles at a right angle
- Material:  
Anodised aluminium



### Info.

- Supplied without fixing kit (see button head screw **BHC8-16/SS/B** or **BHC8-20/SS** and slot nut **PRF-ECL-M8/SS**)

Anodised aluminium

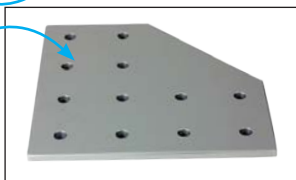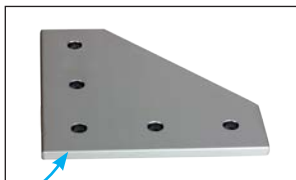

Typical application

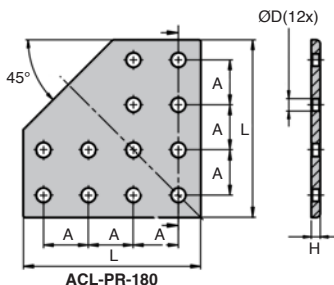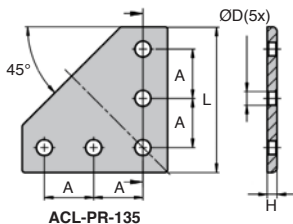

### DISCOUNTS

Qty	1+	50+	100+
Disc. Net	-5%	On request	

Part N°	L	H	A	ØD	Weight (g)	Price each 1 to 49
ACL-PR-135	133	6	45	9	215	13,63 €
ACL-PR-180	178	6	45	9	435	22,16 €

All dimensions in mm

 
## Our other products



FIRSTDC1Q60  
Speed controller 10A,  
10 A



HAS  
Captive C washer,  
Slotted flat headed  
shoulder screw



RBN  
Wheel, Rubber tyre -  
Polypropylene rim



BEAB  
Knob star grip  
antibacterial, Star,  
anti-bacterial



PRF\_CLIP\_22  
Cable clip for  
aluminium profile, For  
electric and  
pneumatic cables



ERF  
Quick fitting threaded  
cable terminal, Cable  
terminal with  
threaded ...



SFWR  
End support, Surface  
mounting



CHMR30  
Worm and wheel gear  
reducer, up to 28 Nm



PCS\_PA6  
Plastic sprocket,  
12.7mm (DIN 08B-1)



EMR  
Fast-locking knurled  
nut, Knurled



PRF-P  
Aluminium profile feet  
support, For feet or



PRF\_SDD  
Support for Ø12mm  
Prox detector, Ø12

## Complementary products



BHC  
Socket head button  
screw, Stainless steel  
A2



PRF\_ECL  
Nut for aluminium  
profile, Stainless steel  
square nut with tab



ACL-PL  
Joining plate for  
aluminium profile,  
Joint plate - 176x86  
mm



ACL-PL  
Joining plate for  
aluminium profile,  
Joint plate - 86x86  
mm