

Connection plate for aluminium profile

ACLPR

Right angled connection

- **Corner reinforcement**
- Connection of 2 aluminium profiles at a right angle
- Material:
Anodised aluminium



Info.

- Supplied without fixing kit (see button head screw **BHC8-16/SS/B** or **BHC8-20/SS** and slot nut **PRF-ECL-M8/SS**)

Anodised aluminium



Typical application

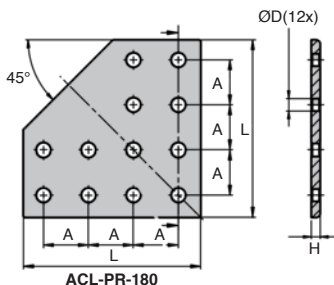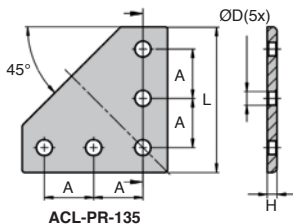

DISCOUNTS

Qty	1+	50+	100+
Disc. Net	-5%	On request	

Part N°	L	H	A	ØD	Weight (g)	Price each 1 to 49
ACL-PR-135	133	6	45	9	215	13,63 €
ACL-PR-180	178	6	45	9	435	22,16 €


All dimensions in mm

Our other products



ETQ

Magnetic label holder for aluminium profile, Label holder

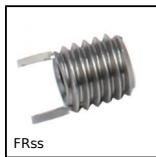

FRss

Stainless steel thread inserts, Stainless steel



MPE

Hexagonal spacer, Steel



S2B

Short linear bearing housing, Closed - Slim



 
PNA

PERIFLEX® elastic coupling, Complete coupling



GMK17_BR

Clamp for guiding profile, Rounded only - single




PRZ

Wear strip for slat top chain, Z profile to be clipped



SLV

 Vertical toggle clamp, Vertical Lever Clamp - steel



BOX-TOR-TOOL

Box set of tool for Nitrile O-rings,



NKX

Combined bearing without inner ring,



HTD14M_55

HTD Heavy duty timing pulley, HTD14



CHCSS

Socket headed screw, Stainless steel - A2

Complementary products



BHC

Socket head button screw, Stainless steel A2



PRF_ECL

Nut for aluminium profile, Stainless steel square nut with tab



ACL-PL

Joining plate for aluminium profile, Joint plate - 176x86 mm



ACL-PR

Joining plate for aluminium profile, Right angled connection