



Joint for aluminium profiles

Corner and variable angle hinge

ACLEAV ACLPV

- Components for creating angled joints
- Material

Corner : Cast aluminium

Hinge : chromed steel

Advantages

- Adjustable angle

Info




- No mounting screws supplied
(see PRF-ECL-M8/ screw FHC8 and CHC8)



ACL-EAV-45



ACL-PAV-130

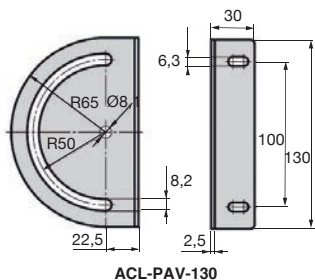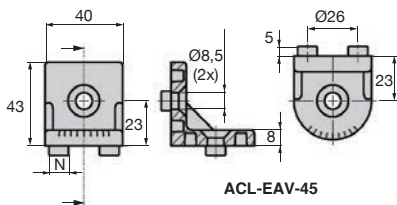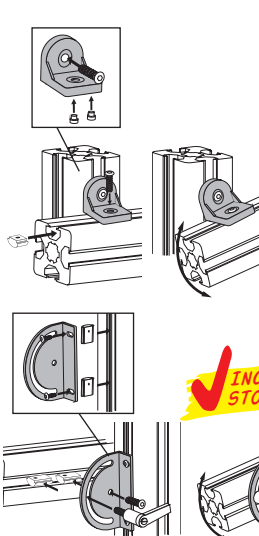

DISCOUNTS

Qty	1+	50+	100+
Disc.	List	-5%	On request

Part number	Type	Screw size	N	Weight (g)	Stock*	Price each 1 to 49
ACL-EAV-45	Equerre	M8	8/10	44	✓	3,90 €
ACL-PAV-130	Pivot	M8	-	221	✓	7,25 €

Dimensions in mm

Our other products



NSKB

Drylin® Rail end cap,
Rail end cap



COA-COG

Surface mounting
plate, Surface
mounting plate for
ball joint



PRF4545

Standard aluminium
profile, 45 x 45 mm



INS_SS

Self tapping stainless
steel insert, 316
stainless steel



DPAR_DKON

Progressive stop,
Steel



BEK

Bearing housing for
miniature ballscrew,
Bearing housing




TCL-ECL

Support rod for heavy
loads, Support spindle




BLHT20

 Right angled gearbox,
from 0.66 to 1.77 Nm



AC

 Strike for toggle latch,
15mm



CXS

External circlip
DIN471, external DIN
471



PF55

Worm and wheel gear
reducer, up to 57 Nm



GCL

Linear ball slide Eco
Range, economy
range

Complementary products



PRF4545

Standard aluminium
profile, 45 x 45 mm



PRF_ECL

Nut for aluminium
profile, Steel square
nut with tab