



# Joint for aluminium profiles

## Corner and variable angle hinge

# ACLEAV ACLPV

- Components for creating angled joints
- Material

Corner : Cast aluminium

Hinge : chromed steel

### Advantages

- Adjustable angle

### Info




- No mounting screws supplied  
(see PRF-ECL-M8/ screw FHC8 and CHC8)



ACL-EAV-45



ACL-PAV-130

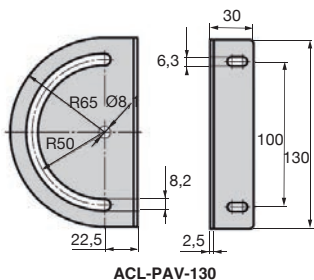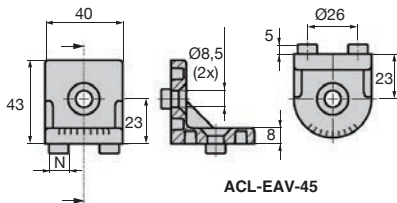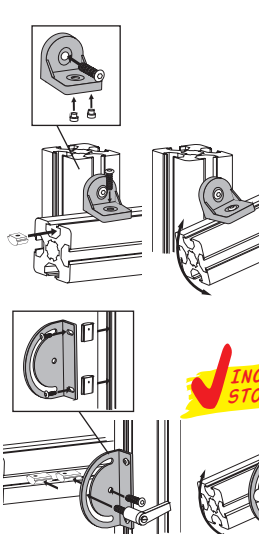

### DISCOUNTS

Qty	1+	50+	100+
Disc.	List	-5%	On request

Part number	Type	Screw size	N	Weight (g)	Stock*	Price each 1 to 49
ACL-EAV-45	Equerre	M8	8/10	44	✓	3,90 €
ACL-PAV-130	Pivot	M8	-	221	✓	7,25 €

Dimensions in mm

## Our other products



PRF-SCL

Lock for aluminium profile, Lock for sliding doors



CMM

Male rod ends DIN ISO12240-4, Steel / bronze



WJUM20

Drylin® W bearing block, Slide



DCG

Suction cup, 2.5 bellows, silicon



 
CHAC4040NP

Square hinge with riveted pin, not drilled, Square with riveted pin,...



HW\_HT

Half-rail guide, Rail



PF40

Worm and wheel gear reducer, up to 18 Nm



IN0

Internal gear, Steel 20NCD2



TUBE25\_25

Square Tube, Aluminium or Steel



SFWR

End support, Surface mounting



TBD

Manual leadscrew table with opposing



HG5-ECO

Eco range Spur gear, Steel C45

## Complementary products



PRF4545

Standard aluminium profile, 45 x 45 mm



PRF\_ECL

Nut for aluminium profile, Steel square nut with tab