



Joint for aluminium profiles

Corner and variable angle hinge

ACLEAV ACLPV

- Components for creating angled joints
- Material

Corner : Cast aluminium

Hinge : chromed steel

Advantages

- Adjustable angle

Info




- No mounting screws supplied
(see PRF-ECL-M8/ screw FHC8 and CHC8)



ACL-EAV-45



ACL-PAV-130

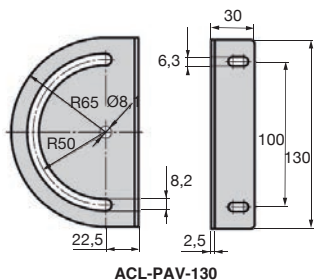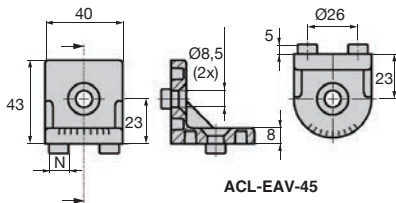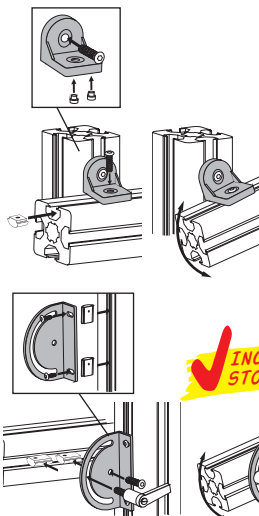

DISCOUNTS

Qty	1+	50+	100+
Disc.	List	-5%	On request

Part number	Type	Screw size	N	Weight (g)	Stock*	Price each 1 to 49
ACL-EAV-45	Equerre	M8	8/10	44	✓	3,90 €
ACL-PAV-130	Pivot	M8	-	221	✓	7,25 €

Dimensions in mm

Our other products



SCR

Suction cup threaded insert, Adaptor for insert



DOMI120

Accessories, Turntable



BCAss

Stainless steel splined bush, Inox



KKSS

Rounded end feather key, Stainless steel



NPTR

Adjustable cross clamp, Adjustable



SHN

Hexagonal nut DIN934, A2 Stainless steel



KB_WW

Closed linear precision bearing, Economy range



 
VTSM

Ball head screws Hygienic Design®, Stainless steel



GARBAB

Lock pin for clamping, Ball lock pin



GPLny

Brush, nylon



NPTR_M

Adjustable cross clamp, Adjustable



TBD

Manual leadscrew table with opposing threads, 5kg

Complementary products



PRF4545

Standard aluminium profile, 45 x 45 mm



PRF_ECL

Nut for aluminium profile, Steel square nut with tab