

Connection plate for aluminium profile

ACLPR

Right angled connection

- **Corner reinforcement**
- Connection of 2 aluminium profiles at a right angle
- Material:
Anodised aluminium



Info.

- Supplied without fixing kit (see button head screw **BHC8-16/SS/B** or **BHC8-20/SS** and slot nut **PRF-ECL-M8/SS**)

Anodised aluminium



Typical application

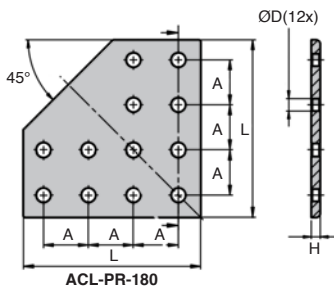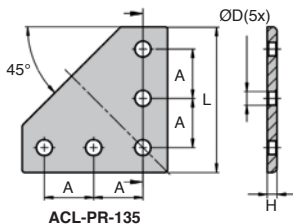

DISCOUNTS

Qty	1+	50+	100+
Disc. Net	-5%	On request	

Part N°	L	H	A	ØD	Weight (g)	Price each 1 to 49
ACL-PR-135	133	6	45	9	215	13,63 €
ACL-PR-180	178	6	45	9	435	22,16 €

All dimensions in mm

Our other products



PRES2HR

Manual workbench press, Force up to 200kg



BAGtr

Lead screw clamping collar, Aluminium



H02

Single needle roller universal joint, Heavy duty



ACL-PLAngle

Joining plate for aluminium profile, Angle connection



SBS_L

Chain link, Stainless steel



PRF_ROUL

Castor for aluminium profile, No brake



BABFCFO

Ball pin socket, Mounting collar with a oval flange



ZG0

Plastic spur gear, Machined plastic (delrin)



DKN

Bellows coupling Gerwah®, from 0.4 to 10Nm




GE1006

Elastic ringed latch, Hooks into a slot



H1

 Crossed helical gear crossed axis at 90°, Machined plastic



BLHM20

Right angled gearbox, double output shafts, up to 1.77 Nm

Complementary products



BHC

Socket head button screw, Stainless steel A2



PRF_ECL

Nut for aluminium profile, Stainless steel square nut with tab



ACL-PL

Joining plate for aluminium profile, Joint plate - 176x86 mm



ACL-PR

Joining plate for aluminium profile, Right angled connection