

# Adjustable foot for aluminium profile

## ACLALF

- Mounting foot for aluminium structures that can be adjusted without tools
- Material:  
Black fibreglass reinforced Nylon PA




### Advantages

- Easy to assemble in central tapped hole of PRF4545 aluminium profile
- Supports up to 150 kg

**NEW!**



**Ideal for workstations**

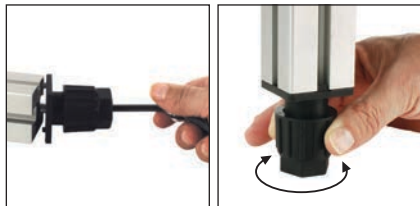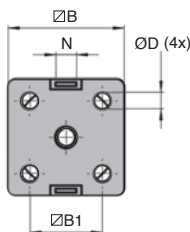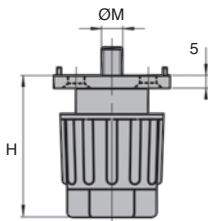

Assembly

### DISCOUNTS

Qty	1+	50+	100+
Disc.	List	-5%	On request

Part number	B	H	N	ØM	B1	ØD	Max load (kg)	Weight (g)	Price each 1 to 49
ACL-ALF45-8-M8	45	45-65	8	M8	28	6.5	150	80	5,25 €

Dimensions in mm

## Our other products



HTD8M\_30

HTD Heavy duty timing pulley, HTD8 Steel



SSDB

Stainless steel bevel gear, 2:1



BABA

Ball pin lifting ring, Steel



PRF JL6

Lip seal for panel, Door seal - Ø 6mm



SH2

Parallel axis helical gear, Machined plastic (delrin)



NCT

Square tube connector, Fixed angle



TBEBASE

Base plate for economic mini-table, Allows X-Y cross tables



PAL

Self locking counter nut, For axial locking



PLM-SC

Magnetic stud with threaded hole, With threaded hole



 
FRtool

Tool for thread repair inserts, Assembly tool



WING

Manually tightened wing nut, Steel (ANSI B18-17)



PRT-TO

igidur® slewing ring, With external teeth- Iglidur®, aluminium & S...

## Complementary products



PRF4545\_P

Stripp Aluminium profile with extendable slot, 45 x 45 mm