

# Adjustable foot for aluminium profile

## ACLALF

- Mounting foot for aluminium structures that can be adjusted without tools
- Material:  
Black fibreglass reinforced Nylon PA




### Advantages

- Easy to assemble in central tapped hole of PRF4545 aluminium profile
- Supports up to 150 kg

**NEW!**



**Ideal for workstations**

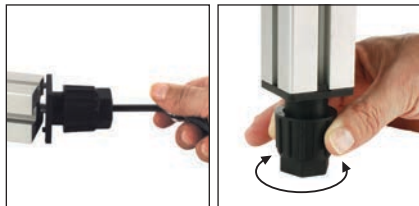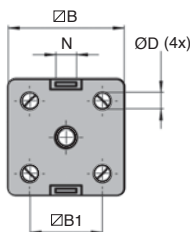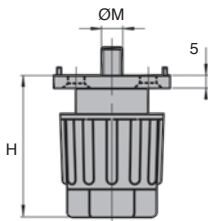

Assembly

### DISCOUNTS

Qty	1+	50+	100+
Disc.	List	-5%	On request

Part number	B	H	N	ØM	B1	ØD	Max load (kg)	Weight (g)	Price each 1 to 49
ACL-ALF45-8-M8	45	45-65	8	M8	28	6.5	150	80	5,25 €

Dimensions in mm

## Our other products



CHB

Worm and wheel gear reducer, up to 41 Nm



RAM30

Manual bevel gearbox, Bevel



BOX-TOR-B

Box set of Nitrile O-rings in nitrile, 20.38 x 1.78mm to 50.16 x 5.34



BH01

Single housed bearing, Bearing fitted with adhesive



ABL100005

Antistatic brush, Standard



 
DB

Steel bevel gear, 2:1



PRF\_PL\_4590

Joining plate for aluminium profile, Joint plate - 45x90 mm



M2

Worm and wheel set, Bronze



 
BRI

Panel holder, Panel holder



CABPVC

PVC covered galvanised steel



SCA

Flat cable clamp, Steel



CHA\_GC\_9SS

Stainless steel garnet hinge, To be welded

## Complementary products

transparen...



PRF4545\_P

Stripp Aluminium profile with extendable slot, 45 x 45 mm